

FREE MOUNT CYLINDER FOR VACUUM SERIES ZCDUK



- ✓ Vacuum connection through piston rod
- ✓ Precise and direct mounting
- ✓ Non-rotating piston rod
- ✓ Bore sizes Ø10-32mm
- ✓ Autoswitches available



TECHNICAL SPECIFICATIONS

Cylinder bore (mm)	10, 16, 20, 25, 32				
Type	Double acting type/Non-rotating piston rod				
Fluid	Air				
Proof pressure	10.5kgf/cm ² (1050kPa)				
Max. operating pressure	7kgf/cm ² (700kPa)				
Min. operating pressure	Ø10, Ø16, - 0.7kgf/cm ² (70kPa) Ø20, Ø25, Ø32 - 0.6kgf/cm ²				
Vacuum port pressure	-760 mmHg - 6kgf/cm ²				
Ambient and fluid temperature	5 ~ 60°C				
Lubrication	Not required				
Cushion	Both side rubber cushion				
Stroke allowance	+1.0 0				
Thread tolerance	JIS 2 Class				
Rod tip screw : Yes or No	Yes, No (Pad direct mounting)				
Mounting	Basic type				
Non-rotating piston rod accuracy	Ø10	Ø16	Ø20	Ø25	Ø32
	±0.8°		±0.5°		

How To ORDER SERIES ZCDUK

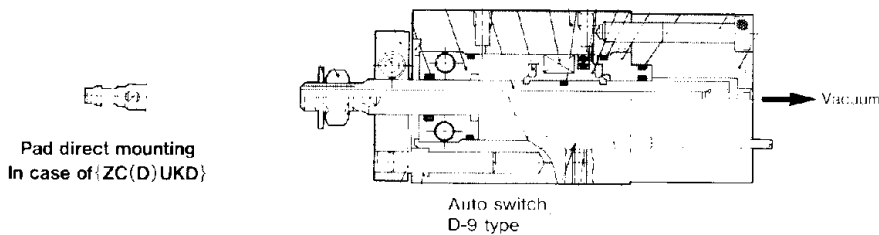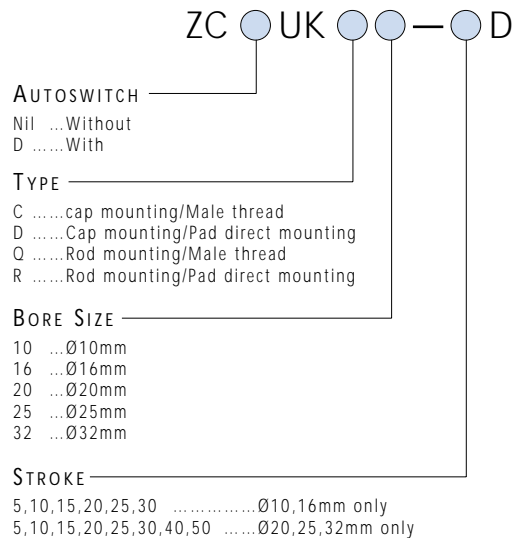

For cap type mounting, care should be taken not to exceed 6 bar when ejecting the workpiece

STOCKED PRODUCTS

FOR A LIST OF STOCKED PRODUCTS, PLEASE SEE THE CURRENT SMC PRICE LIST

ACCESSORIES

SERIES ZCDUK
 See cylinder Series CDU

STOCKED PRODUCTS

FOR A LIST OF STOCKED PRODUCTS, PLEASE SEE THE CURRENT SMC PRICE LIST



SEE INSIDE FRONT COVER FOR
 DETAILS OF YOUR LOCAL SALES OFFICE



FOR FURTHER TECHNICAL
 DETAILS ON THIS
 PRODUCT CONTACT
 YOUR LOCAL REGIONAL
 CENTRE