


# Terminal block

Item number: 261-106/341-000  
Marking: 2 CONDUCTOR MODULAR TERMINAL STRIP WITH  
FIXING FLANGES - 6 POLE  
WITH PUSH-BUTTONS ON BOTH SIDES  
Colour: grey

## Product picture

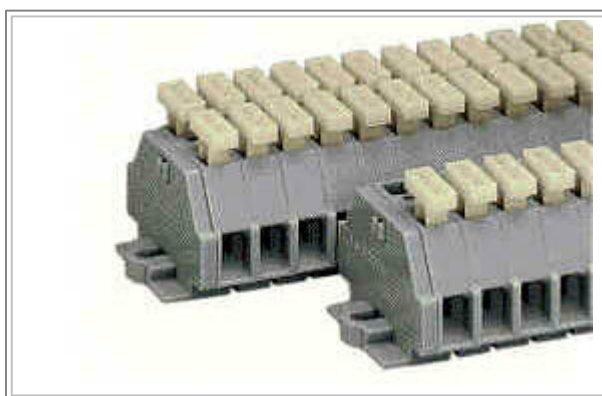

## Technical Data

Wiring:	Side-entry		
Minimum cross section [mm <sup>2</sup> ]:	0.08	Max. conductor cross section [mm <sup>2</sup> ]:	2.5
Minimum cross section [AWG]:	28	Max. conductor cross section [AWG]:	14
Number of Clamping Units:	2	Number of Potentials:	6
Height: [mm]:	23.2	Height: [inch]:	0.914
Width: [mm]:	6	Width: [inch]:	0.236
Depth [mm]:	28	Depth [inch]:	1.103
Nominal Voltage [V]:		Blocking Voltage [V]:	
Rated voltage EN [V]:	500	Rated voltage UL [V]:	300
Rated voltage CSA [V]:	300	Rated search voltage [kV]:	6
Current (Amps.) EN [A]:	24	Current (Amps.) UL [A]:	15
Current (Amps.) CSA [A]:	10	Pollution degree:	3
Stripped length [mm]:	8-9	Stripped length [inch]:	0.33

## [Accessories](#)



© WAGO Kontakttechnik GmbH, 1998  
98-06-29

Webmaster: [webmaster@wago.com](mailto:webmaster@wago.com)

Site Engineering: [Siemens AG](#) E-Mail: [ps2@hvrtd.siemens.de](mailto:ps2@hvrtd.siemens.de)