
 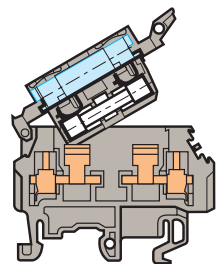


M4/8.SF screw clamp terminal blocks

For 5x20 and 5x25 fuses - With blown fuse indicator

8 mm 0.315 in spacing



8 mm 0.315 in spacing

With blown fuse indicator



Ordering details

| Description | Color | Type | Order code | Pkg pce | Weight (1 pce) g |
|--|-------------------------------|----------|-----------------|---------|------------------|
| Fuse With blown fuse indicator by neon 110-230 V | Grey <input type="checkbox"/> | M4/8.SFL | 1SNA115661R2100 | 50 | 14.00 |
| With blown fuse indicator by LED 24 V AC/DC | Grey <input type="checkbox"/> | M4/8.SFD | 1SNA115663R2300 | 50 | 14.00 |

| Main technical data | IEC | UL | CSA | Leakage current : |
|---------------------------|--------|--------|-------|-------------------|
| Rated voltage | 400 V | 600 V | 250 V | 24 V : < 4.5 mA |
| Impulse withstand voltage | 4000 V | | | 110 V : < 0.5 mA |
| Protection | IP20 | NEMA 1 | | 230 V : < 0.7 mA |



 2

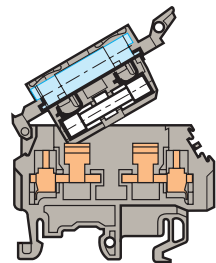

8 mm 0.315 in spacing

With blown fuse indicator and 2 test socket DIA 2 mm 0.079 in

Ordering details

| Description | Color | Type | Order code | Pkg pce | Weight (1 pce) g |
|---|-------------------------------|-----------|-----------------|---------|------------------|
| Fuse With blown fuse indicator by LED 24 V and 2 test socket DIA 2 mm 0.079 in | Grey <input type="checkbox"/> | M4/8.SFDT | 1SNA115665R2500 | 50 | 14.00 |
| With blown fuse indicator by neon 110-230 V and 2 test socket DIA 2 mm 0.079 in | Grey <input type="checkbox"/> | M4/8.SFLT | 1SNA115667R2700 | 50 | 14.00 |

| Main technical data | IEC | UL | CSA | Leakage current : |
|---------------------------|--------|--------|-------|-------------------|
| Rated voltage | 400 V | 600 V | 250 V | 24 V : < 4.5 mA |
| Impulse withstand voltage | 4000 V | | | 110 V : < 0.5 mA |
| Protection | IP20 | NEMA 1 | | 230 V : < 0.7 mA |



Accessories

| Description | Color | Type | Order code | Pkg pce | Weight (1 pce) g |
|--------------------------------|---|------|-----------------|---------|------------------|
| 1 Test plugs DIA 2 mm 0.079 in | Black <input checked="" type="checkbox"/> | FC2 | 1SNA007865R2600 | 100 | |



1

All the technical data for UL/CSA standard and dimensions in inches are in italic.
Technical data valid for copper conductors only.