

21 51 06

Thread/Thread Unions

Union End: PVC-U, BSP parallel female thread (Rp)

Union Bush: PVC-U, BSP parallel female thread (Rp)

Union Nut: PVC-U

Gasket: O-ring No. 48 41 00 EPDM see page 8.13

Can be delivered additionally if required:

O-ring No. 49 41 00 FPM see page 8.13

Connection to plastic thread only

Do not use thread sealing pastes that are harmful to PVC-U

Rp	PN	Code	£	SP	GP	g	z ₁	z ₂	G	D	l ₁	l ₂
1/4"	10	721.510.604				16	3	12	5/8"	31	15	22
3/8"	10	721.510.605				25	3	13	3/4"	35	17	24
1/2"	10	721.510.606				43	3	13	1"	43	19	26
3/4"	10	721.510.607				65	3	14	1 1/4"	53	22	29
1"	10	721.510.608				95	3	15	1 1/2"	60	25	32
1 1/4"	10	721.510.609				168	3	19	2"	74	29	38
1 1/2"	10	721.510.610				220	3	26	2 1/4"	83	34	45
2"	10	721.510.611				400	3	33	2 3/4"	103	41	56

21 91 08

Reducing Bush

with BSP taper male thread (Rp) and BSP parallel female thread (R)



Connection to plastic thread only

Do not use thread sealing pastes that are harmful to PVC-U

Size	PN	Code	£	SP	GP	g	z	l	s
1/2 x 3/8		721.910.834				15	25	36	27
3/4 x 1/2		721.910.835				22	25	39	32
1 x 1/2		721.910.842				28	31	45	32
1 x 3/4		721.910.841				31	29	45	36
1 1/4 x 1		721.910.846				60	32	50	46
1 1/2 x 1 1/4		721.910.852				72	35	55	55
2 x 1 1/2		721.910.858				123	45	65	65

21 91 19

Hexagon Nipples

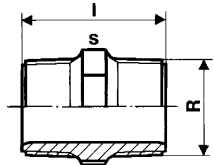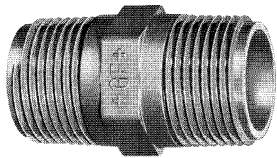

with BSP taper male thread (R)

Connection to plastic thread only

Do not use thread sealing pastes that are harmful to PVC-U

R	PN	Code	£	SP	GP	g	l	s
3/8"	10	721.911.905				8	37	19
1/2"	10	721.911.906				13	45	22
3/4"	10	721.911.907				19	49	27
1"	10	721.911.908				35	57	36
1 1/4"	10	721.911.909				51	62	46
1 1/2"	10	721.911.910				70	67	50
2"	10	721.911.911				125	76	65