


DESKTOP & INSTRUMENT CASES

Desktop Instrument Cases


Extensive range of high quality instrument cases for test, measurement, display and control applications. Functional push-fit construction designed for quick and easy assembly.

- Screwless push-fit assembly via 8x lock pins
- Horizontal PCB guides in side profiles
- Ventilation slots in lid and base
- Lid and base can be dismantled independently from each other
- 4x non-slip feet as standard (CDIC00001-4)
- 2x non-slip feet, 2x tilting feet and front handles as standard (CDIC00005-7)

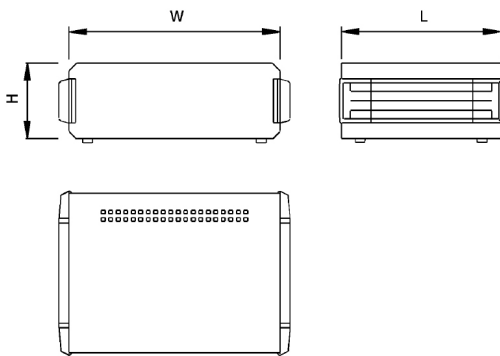

Assembly Plate

- The assembly panel is easily fixed to the enclosure using M3 screws and nuts
- 1 mm thick steel, zinc coated

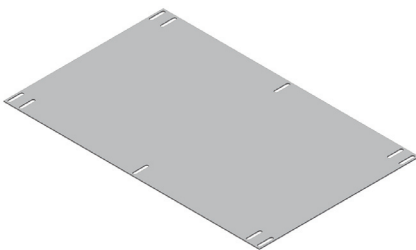

SPECIFICATION		
Material	High impact ABS. UL94-V0 Lid & base 1mm thick steel, epoxy coated, textured Side profiles extruded 6063 aluminium, matt silver anodised Brackets & tilting feet	
Material sizes 1-4	CDIC00001-4	Front/rear panels 1mm thick 5050 aluminium, silver anodised
Material sizes 5-7	CDIC00005-7	Front/rear panels 2mm thick 5050 aluminium, silver anodised
Standard unit sizes 1-4	CDIC00001-4	Lid & base 2x front/rear panels 2x aluminium side profiles 4x brackets 8x lock pins 4x non-slip feet
Standard unit sizes 5-7	CDIC00005-7	Lid & base 2x front/rear panels 2x aluminium side profiles 2x rear brackets 2x front brackets with handle 2x non-slip feet 2x non-slip tilting feet 8 x locking pins

DARK GREY	LENGTH	WIDTH	HEIGHT
CDIC00001	140mm	150mm	70mm
CDIC00002	200mm	200mm	70mm
CDIC00003	170mm	225mm	80mm
CDIC00004	200mm	250mm	90mm
CDIC00005	220mm	300mm	100mm
CDIC00006	260mm	350mm	120mm
CDIC00007	300mm	400mm	130mm

PART NO.	LENGTH	WIDTH
CDICMP002	143mm	192mm
CDICMP003	113mm	217mm
CDICMP004	143mm	242mm
CDICMP005	170mm	286.5mm
CDICMP006	210mm	336.5mm
CDICMP007	250mm	386.5mm



+44 (0)1638 716101
info@camdenboss.com
www.camdenboss.com

We operate a constant improvement policy, our products are subject to change without notice.

Ver 1.0

