

03

03 Combination Pliers

DIN ISO 5746

- ▶ with gripping zones for flat and round material, suitable for versatile use
- ▶ with cutting edges for soft and hard wire
- ▶ long cutting edges for thicker cables
- ▶ cutting edges additionally induction hardened, cutting edge hardness approx. 60 HRC
- ▶ special tool steel, oil-hardened and tempered



03 01 180



03 02 180




03 05 180




03 06 180



Gripping zone for flat material

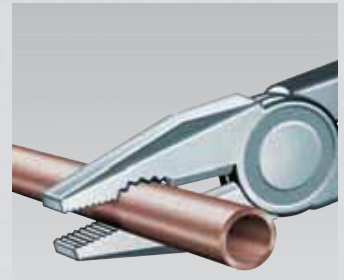

Gripping zone for round material

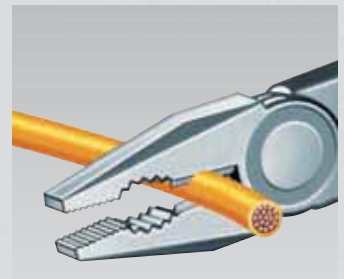

Cutting edges for wire and cable

Article-No.	EAN-Code	Head	Handles	Cutting capacities				g
				⊘ mm	⊘ mm	⊘ mm	mm ²	
03 00	180	polished	black atramentized	3.4	2.2	12.0	16.0	210
	200			3.8	2.5	13.0	16.0	260
	250			3.8	2.5	15.0	25.0	440
03 01	140	polished	plastic coated	2.8	1.8	9.0	10.0	110
	160			3.1	2.0	10.0	16.0	180
	180			3.4	2.2	12.0	16.0	220
	200			3.8	2.5	13.0	16.0	280
	250			3.8	2.5	15.0	25.0	480
03 02	160	polished	with two-colour dual component handles	3.1	2.0	10.0	16.0	215
	180			3.4	2.2	12.0	16.0	260
	200			3.8	2.5	13.0	16.0	330
03 05	140	chrome plated	with two-colour dual component handles	2.8	1.8	9.0	10.0	135
	160			3.1	2.0	10.0	16.0	215
	180			3.4	2.2	12.0	16.0	260
	200			3.8	2.5	13.0	16.0	330
03 06	160	chrome plated	insulated with two-colour dual component handles	3.1	2.0	10.0	16.0	220
	180			3.4	2.2	12.0	16.0	265
	200			3.8	2.5	13.0	16.0	335
03 07	160	chrome plated	plastic dipped insulated	3.1	2.0	10.0	16.0	265
	180			3.4	2.2	12.0	16.0	305
	200			3.8	2.5	13.0	16.0	380
	250			3.8	2.5	15.0	25.0	610