

# Mini Thermometers and Thermometer Strips




## Thermometer Strips

Self-adhesive foils with temperature sensitive elements for temperature control and regulation, ideal for monitoring batches during cooking or temperature checks in warehouses and during transportation.

- Measuring range +37 to +280 °C
- Irreversible change in colour within 2 seconds
- Booklet of 10 thermometer strips

Quantity discounts and rolls available. Please call for further information.

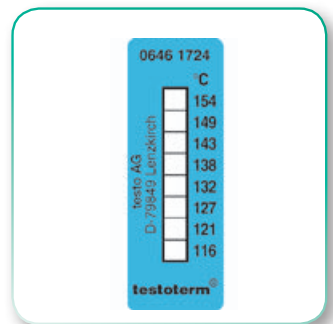

Testoterm Strips	Part Number	
+37 to +65 °C	0646 0108	
+71 to +110 °C	0646 0916	
+116 to +154 °C	0646 1724	
+161 to +204 °C	0646 2532	
+204 to +260 °C	0646 3341	
+249 to +280 °C	0646 0005	



01420 544 433 • [info@testo.co.uk](mailto:info@testo.co.uk) • [www.testo.co.uk](http://www.testo.co.uk) • [www.testodirect.co.uk](http://www.testodirect.co.uk)



## Thermometer strips

testoterm thermometer strips are self-adhesive foils with temperature sensitive elements for temperature control and regulation. Used, for example, for measurements on moving parts, for long-term monitoring and on small parts.

**+37 to +65 °C**

Part no. 0646 0108

**+71 to +110 °C**

Part no. 0646 0916

**+116 to +154 °C**

Part no. 0646 1724

**+161 to +204 °C**

Part no. 0646 2532

**+204 to +260 °C**

Part no. 0646 3341

**+249 to +280 °C**

Part no. 0646 0005

## Self-adhesive foils

- Irreversible change in colour within 1 second
- Practical booklet with 10 thermometer strips
- Thermometer strips available on rolls, e.g. for labelling machines







### Technical data

Accuracy: From +43°C to +154°C:  $\pm 1.5^\circ\text{C}$ ; from +160°C:  $\pm 1\% \pm 1^\circ\text{C}$  of respective temperature reading

Max. operating temperature corresponds to the respective measuring ranges

Storage of clock indicators: Up to +65°C, max. 9 months; other measuring ranges: up to 2 years; max. storage temperature +25°C. Storage in a refrigerator is recommended.

l x w: 50 x 18 mm or 39 x 18 mm

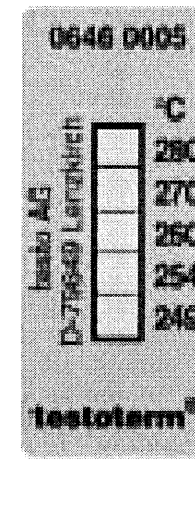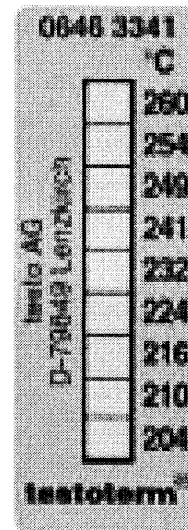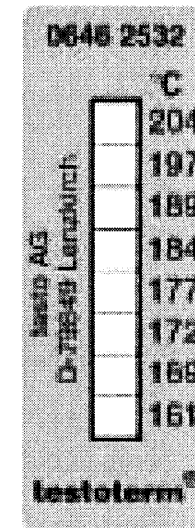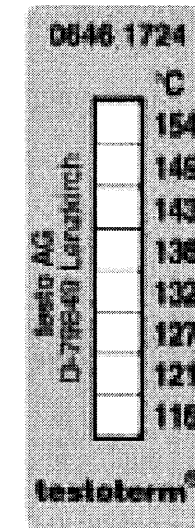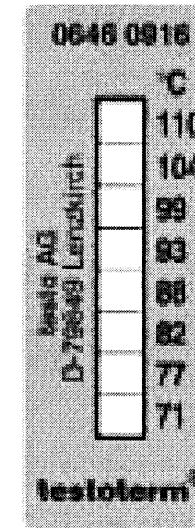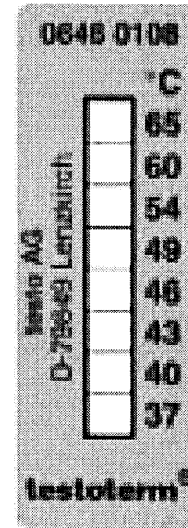

### Ordering data/Quantity discount

1 to 4 booklets (with 10 each)

5 to 9 booklets (with 10 each)

10 to 19 booklets (with 10 each)

20 to 49 booklets (with 10 each)

50 to 99 booklets (with 10 each)

1000 on a roll

Actual size