


Deep groove ball bearings, single row, shield on both sides

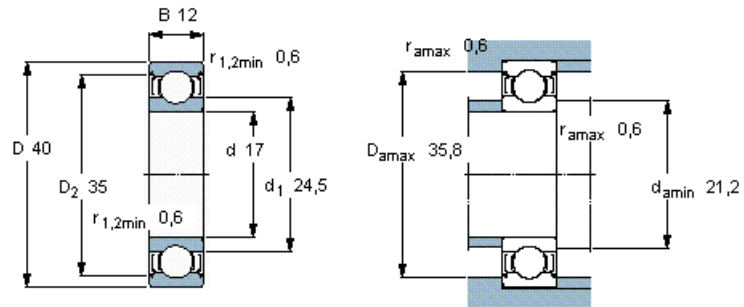

Principal dimensions			Basic load ratings		Fatigue load limit P_u	Speed ratings		Mass	Designation
d	D	B	dynamic	static		Reference speed	Limiting speed		
mm			C	C_0	kN	r/min	kg	-	* - SKF Explorer bearing
17	40	12	9,95	4,75	0,2	38000	19000	0,065	6203-2Z *



Calculation factors

$k_r = 0,025$

$f_0 = 13$