

Bench grinders

Shop line

Last update : 15/01/07








Guaranteed
2 years


> GRINDING WHEEL - BRUSH MACHINES

TM 150 B / TM 200 B / TM 200 BT

Characteristics :

- Semi steel body
- Mounted on sealed self-lubricating ball bearings
- Undervoltage coil switch
- Polycarbonate protection shield
- Internal thermal protection of motor
- Pressed steel housings with dust evacuation nozzle
- Safety/compliance:
 - space between grinder and housing less than 5 mm
- Spark screen adjustable to 2 mm from grinder
- No access opening to tool holder

| |   (mm) | Grinders grain | Type of brush wire | Motor power (kw) |  | Rotation speed (rpm) |  (kg) | Dimensions a x b x c (mm) |  |
|------------------|---|----------------|--------------------|------------------|---|----------------------|---|---------------------------|---|
| TM 150 B | 150 x 25 x 32 | AA 60 M | Acier laitonné | 0,52 | 230 v mono | 2800 | 14 | 525 x 260 x 220 | 20113102 |
| TM 200 B | 200 x 30 x 32 | AA 60 M | Acier laitonné | 0,9 | 230 v mono | 2800 | 27,5 | 570 x 330 x 265 | 20113104 |
| TM 200 BT | 200 x 30 x 32 | AA 60 M | Acier laitonné | 0,9 | 400 v tri | 2800 | 27,5 | 570 x 330 x 265 | 20113109 |

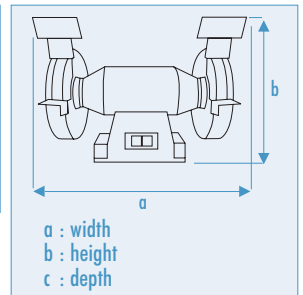

TM 150 B



TM 200 B
TM 200 BT




Conseils d'utilisation :
As a safety precaution, the machine must be solidly attached to a base or a workbench.


Consommables :

• Base :

| | Height x Width x Depth (mm) |  (kg) |  |
|------------|-----------------------------|---|---|
| S 2 | 845 x 360 x 360 | 13 | 20198075 |

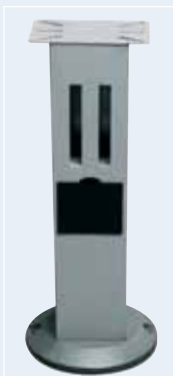

• Bit sharpener*:

| |  |
|----------------------|--|
| Bit sharpener | 20198072 |



* Bit sharpener for spot use to attach on the workbench next to the grinder. For guiding the sharpening of 3 to 18 mm diameter drill bits. Angle adjustable from 41° to 88°