

KAD1H

operating head 60 x 60 mm - black color - black handle - blank for engraving



Main

Range of product	Harmony Series K
Product or component type	Cam switch operating head
Component name	KAD
Product compatibility	Front mounting bodies 12 and 20 A by Ø 22 mm hole
Cam switch head type	With front plate 60 x 60 mm
Type of operator	Black handle, length = 42 mm
Rotary handle padlocking	Without
Presentation of legend	With mat black legend

Complementary

Mechanical durability	1000000 cycles
CAD overall width	60 mm
CAD overall height	60 mm
CAD overall depth	77 mm
Length	42 mm
Product weight	0.053 kg


Environment

Protective treatment	TC
Ambient air temperature for operation	-25...55 °C
Ambient air temperature for storage	-40...70 °C
Shock resistance	30 gn conforming to IEC 68-2-27
Vibration resistance	5 gn, 10...150 Hz conforming to IEC 68-2-6
IP degree of protection	IP65 conforming to IEC 529 IP65 conforming to NF C 20-010
RoHS EUR status	Compliant
RoHS EUR conformity date	0910

The information provided in this documentation contains general descriptions and/or technical characteristics of the products contained herein. This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications. It is the duty of any such user or integrator to perform the appropriate and complete risk analysis, evaluation and testing of the products with respect to the relevant specific application or use thereof. Neither Schneider Electric Industries SAS nor any of its affiliates or subsidiaries shall be responsible or liable for misuse of the information contained herein.

Operating Head

For \varnothing 22 mm/0.87 in. Hole, Front Mounting Body

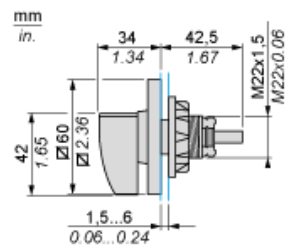

Operating Head

Panel Cut-out

