
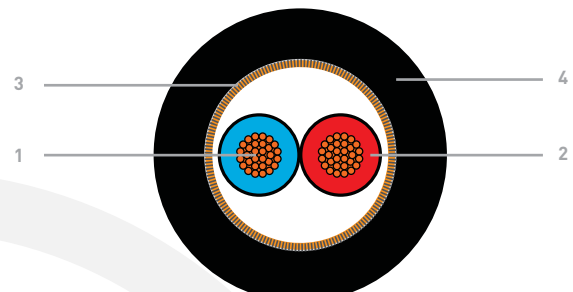


MICROPHONE CABLE: VIPER

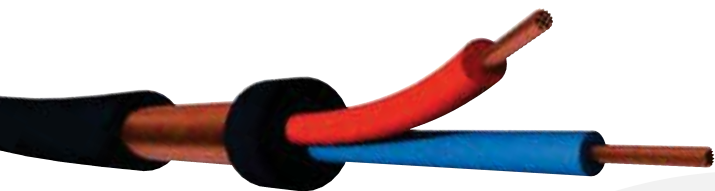

1. Composition of core: 28 x 0.10 mm Bare copper
2. Conductor insulation: Polyethylene
Color coding of conductors: red, blue
3. Shielding: Bare copper spiral shielding

VIPER

APPLICATIONS

- Analog balanced audio links
- Best-seller
- Ideal for on-stage performances

MECHANICAL CHARACTERISTICS

- Operating temperature: -20°C - + 70°C
- Bend radius: Fixed station: 30 mm
Mobile station: 60 mm

PRODUCT ADVANTAGES

- High flexibility
- Very robust
- Easy to wind
- Good resistance to tensile strength
- Designed to be coiled, uncoiled, bend and crushed
- Jacket available in different colors
- Available in cords – ON AIR PRO range

SUITABLE PLUGS

- 3 pins XLR, Jack 6.35 mm, Cinch

Part Nb	Nb of pairs	Section	Jacket	Outer diameter	Weight	Packaging
VIPER	1	0.22 mm ²	Black PVC	6.35 mm	52 kg / km	100 and 500 m
VIPERR	1	0.22 mm ²	Red PVC	6.35 mm	52 kg / km	100 m
VIPERB	1	0.22 mm ²	Blue PVC	6.35 mm	52 kg / km	100 m