


# EDL-11TW - PA Loudspeaker

100V



PA ceiling speaker

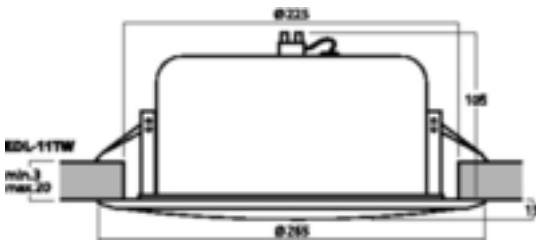

- 100 V line technique
- White, silver or black metal housing
- Including fire protection cover for a high safety level
- Additional integrated tweeter
- Quick-mounting facility
- For a ceiling thickness from 3 to 20 mm



## Technical data

Frequency range	: 60-20,000 Hz
Power capability, 100 V	: 10/5/2.5 W <sub>RMS</sub>
Power capability, 8 Ohm	: -
SPL (1 W/m)	: -
Max. rated SPL	: -
Type of speaker	: 200
Mounting cutout	: Ø 225 mm x 110 mm
Mounting depth	: 105 mm
Admiss. ambient temp.	: 0-40 °C
Dimensions	: Ø 264 mm x 120 mm
Weight	: 1.6 kg
Other features	: -