



Model		
product brand name		SETRON
Main circuit		
Operating frequency / Rated value		
• minimum	Hz	50
• maximum	Hz	60
Operating voltage / Rated value		
• maximum	V	720
Control current		
Control supply voltage		
• with AC / at 50 Hz / Rated value / maximum	V	720
• with AC / at 60 Hz / Rated value / maximum	V	720
Auxiliary circuit		
Number of CO contacts / for auxiliary contacts		0
Number of NC contacts / for auxiliary contacts		0
Number of NO contacts / for auxiliary contacts		0
Suitability		
Suitability for operation		For AC networks
Product function		
Product function / Fault storage		No
Connections		
Type of electrical connection		screw-type terminals

Mechanical Design

Height	mm	32
Width	mm	46
Depth	mm	60

General Product Approval



Declaration of Conformity

Further information

Information- and Downloadcenter (Catalogs, Brochures,...)

<http://www.siemens.com/lowvoltage/catalogs>

Industry Mall (Online ordering system)

<https://eb.automation.siemens.com/mall/en/WW/Catalog/Product/5SV87000KK>

Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<http://support.automation.siemens.com/WW/view/en/5SV87000KK/all>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)


http://www.automation.siemens.com/bilddb/cax_en.aspx?mfb=5SV87000KK

CAX-Online-Generator


<http://www.siemens.com/cax>

Tender specifications

<http://ausschreibungstexte.siemens.com/tiplv>

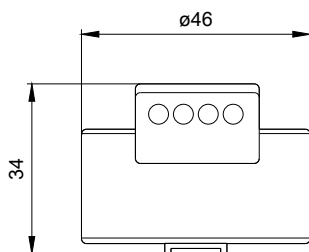

last modified:

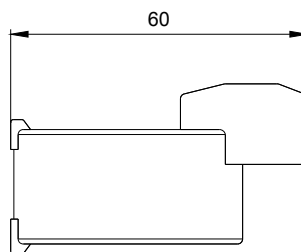

05.05.2015