

## TAPES




### HIGH PERFORMANCE INDUSTRIAL ADHESIVE VINYL TAPE B-580

Adheres to most clean, dry surfaces and also conforms well to irregular, curved or rough surfaces.

- Stands up to grease, oil and most industrial chemicals
- 5-year average outdoor durability in temperatures from -40°C to +82°C\*
- Minimum application temperature: -18°C
- Length 15 m

Reference	Description
042018	13 mm White
042022	13 mm Yellow
042026	13 mm Green
042030	13 mm Red
042034	13 mm Blue
042038	13 mm Orange
042042	13 mm Black
042046	13 mm Grey
042050	13 mm Brown
042054	13 mm Gold
042058	13 mm Purple
042076	13 mm Clear
042019	25 mm White
042023	25 mm Yellow
042027	25 mm Green
042031	25 mm Red
042035	25 mm Blue
042133	25 mm Light Blue
042039	25 mm Orange
042043	25 mm Black
042047	25 mm Grey
042051	25 mm Brown
042055	25 mm Gold
042059	25 mm Purple
042077	25 mm Clear
500000	25 mm Pink
042021	50 mm White
042025	50 mm Yellow
042029	50 mm Green
042033	50 mm Red
042037	50 mm Blue
042134	50 mm Light Blue
042041	50 mm Orange
042045	50 mm Black
042049	50 mm Grey
042053	50 mm Brown
042057	50 mm Gold
042061	50 mm Purple
042079	50 mm Clear
500001	50 mm Pink

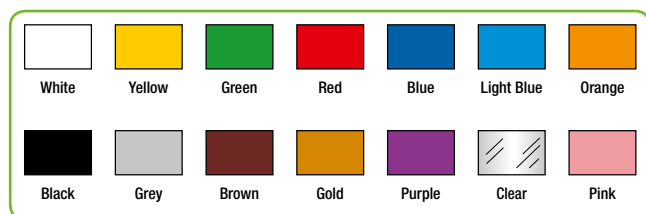

### WHICH SUPPLIES FOR WHAT APPLICATION: PAGE 24-25

\* Depends on climatic conditions, colours and usage

### REPOSITIONABLE VINYL TAPE B-581

 


Special adhesive allows easy removal and re-application

- 5-year average outdoor durability in temperatures from -40°C to +80°C\*
- Minimum application temperature: +10°C
- Length 15 m

Reference	Description
042100	13 mm White
042103	13 mm Yellow
042101	25 mm White
042104	25 mm Yellow
042102	50 mm White
042105	50 mm Yellow

### REFLECTIVE VINYL TAPE B-584



The reflective quality of the material makes it ideal for reading labels in low light conditions (flashlight).

- 5-year average outdoor durability in temperatures from -40°C to +80°C
- Minimum application temperature: White: +10°C  
Yellow and Orange: -18°C
- Length 10 m

Reference	Description
042062	25 mm White
042064	25 mm Yellow
042066	25 mm Orange
042063	50 mm White
042065	50 mm Yellow
042067	50 mm Orange

### ECONOMY POLYPROPYLENE B-529



- Ideal low-cost choice
- Usage in temperatures from -40°C to +80°C
- Minimum application temperature: +10°C
- Length 15 m

Reference	Description
042068	13 mm White
042069	25 mm White
042071	50 mm White

### TAMPER-EVIDENT VINYL B-530



Destructs into tiny fragments when tampered with, making removal very tedious and difficult

- 3-year average outdoor durability in temperatures from -40°C to +80°C\*
- Minimum application temperature: +10°C
- Length 15 m

Reference	Description
042137	13 mm White
042138	25 mm White
042139	50 mm White

### OVERLAMINATE B-966



- 2-year average outdoor durability in temperatures from -40°C to +150°C
- Minimum application temperature: +10°C
- Length 50 m

Reference	Description
266080	50 mm Clear
266081	85 mm Clear
266082	130 mm Clear