

## Standard DIN 23141 Two Module, Single Channel, Weekly Time Switch



### Benefits

---

The 23141 Time Switch is a two module wide general purpose timer that it is perfect for applications where space economy may be a factor. Requires minimum time to set up. They can be used also for lighting of hallways to buildings, garages, toilet ventilation etc.

### Features

---



- Modular case 2 modules, 5 keys.
- Connection by protected cage terminals
- Voltage free changeover contact
- Pivoting transparent hood. Product locking function
- Weekly programming, 56 program steps total per product
- Product supplied with current time and date
- Programmable off circuit
- Automatic summer/winter time change
- Programming by day and group of days
- Power reserve: 5 years
- Permanent override, temporary override
- Bar graph display of daily profile
- Keyboard locking by key pressing or by key
- ON/OFF function

## Technical Data

Supply voltage	230 V AC +/-15%
Frequency	50/60 Hz
Consumption at 50 Hz	6VA
Outputs	Changeover contacts without potential
Insulation between input and output	4kV
Max cutoff power	
AC1	$\mu$ 16 A 250 V AC
fp = 0.6	$\mu$ 10 A 250 V AC
Halogen lamps 230 V	2300W
Incandescent lamps	2300W
Compensated fluo tubes // (max 45 $\mu$ F)	400W
Non-compensated fluo tubes, compensated in series	1000W
Compact fluo lamps	500W
Min cutoff power	
AC1 100mA 250 V AC	
Programming capacity	56 steps
Min time between 2 program steps	1 minutes
Accuracy of operation	1 second per 24 hour
Power reserve	Lithium battery with 5 years reserve
Standby condition	Display OFF after 1 min. without voltage. Return to auto mode when voltage returns, or press button
Protections index	IP20 - IK 3
Operating temperature	-5 °C to 45°C
Storage temperature	-20°C to 70°C
Connection by cage terminals	
Capacity flexible	1 to 6 mm <sup>2</sup>

## Electrical Connections

### Internal Wiring Diagram

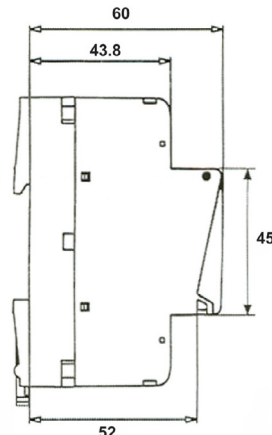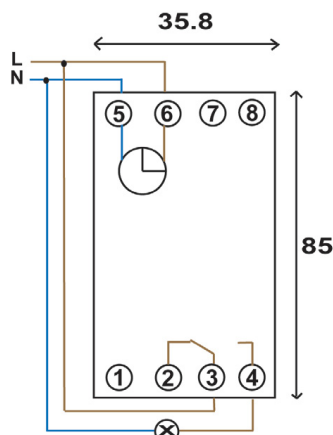

## Technical Helpline: 01475 745131

### CUSTOMER CARE POLICY

As part of Sangamo's continuous improvement program, the Company operates a Customer Care Policy. This means that we welcome your comments and complaints, as it can only help us to improve our services to you, our customer.

**SANGAMO**



Certificate Q05237



Certificate EMS 80426

Sangamo Limited, Industrial Estate, Port Glasgow,  
Renfrewshire PA14 5XG

Tel: 01475 745131 Fax: 01475 744567

Email : enquiries@sangamo.co.uk Web: www.sangamo.co.uk