

Datasheet

150 Piece 1/2 in., 1/4 in., 3/8 in., Square Drive Super Lock Wrench Set

RS Stock number [521-2400](#)



Description:

Drive Size: 1/2 in, 1/4 in, 3/8 in

Drive Type: Square

150-part socket kit with wave profile and ball lock retainer, in three drive sizes


Made of chrome vanadium steel

Special profile grips the flanks instead of the edges of the screw heads

Suitable for Imperial, metric, outer Torx® and also worn screw heads

No sliding, even in difficult usage conditions

Supplied in PE hard shell case

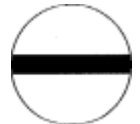

Set Contents

1 x each ratchet handle 72 teeth with square drive:	1/4"; 3/8"; 1/2"
1 x each universal joint with square drive and output:	1/4"; 3/8"; 1/2"
1 x extension 1/4" x 100 mm	
1 x square extension 1/2" x 250 mm and sliding adapter	
1 x each square extension 1/4" x 50 mm; 3/8" x 125 mm; 1/2" x 125 mm	
1 x sliding T-handle with 1/4" output	
1 x each square adapter on hexagon 3/8" x 5/16", 1/2" x 5/16"	
1 x screwdriver handle with 1/4" square drive and output	
1 x angled hexagon:	1.3; 1.5; 2; 2.5; 3; 4; 5 mm
Bit inserts	
1 x each blade, square 1/4":	4; 5.5; 6.5; 7 mm, hexagon 5/16": 8; 10; 12
1 x each PHILLIPS®, square 1/4":	PH0; PH1; PH2; hexagon 5/16": PH3; PH4
1 x each POZIDRIV®, square 1/4":	PZ0; PZ1; PZ2; hexagon 5/16": PZ3; PZ4
1 x each TORX®, square 1/4":	T8; T9; T10; T15; T20; T25; T27; T30 and hexagon 5/16": T40; T45; T50; T55; T60; T70
1 x each TORX-BO®, square 1/4":	T8H; T9H; T10H; T15H; T20H; T25H; T27H; T30H; hexagon 5/16": T40H; T45H; T50H; T55H; T60H; T70H
1 x each Allen, 1/4" square:	3; 4; 5; 6; 5/16" hexagon: 7; 8; 10; 12; 14 mm
Socket inserts	
1 x each 1/4" short:	4; 4.5; 5; 5.5; 6; 7; 8; 9; 10; 11; 12; 13; 14 mm and long: 4; 5; 6; 7; 8; 9; 10 mm
1 x each 3/8" short:	10; 11; 12; 13; 14; 15; 16; 17; 18; 19 mm and long: 10; 11; 12; 13; 14; 15 mm
1 x each 1/2" short:	10; 11; 12; 13; 14; 15; 16; 17; 18; 19; 20; 21; 22; 24; 27; 30; 32 mm and long: 16; 17; 18; 19; 22 mm
1 x spark plug connector:	3/8" x 18; 1/2" x 16; 1/2" x 21 mm
1 x each E-Profile outer TORX®, 1/4":	E4; E5; E6; E7; E8; 3/8": E10; E11; E12; E14; E16 and 1/2": E18; E20; E24