


94V-0
U.L. RATED
MATERIALS

PLP 1 SERIES

Panel Light Pipes, Color: See Chart


- ◆ Protect Circuits From ESD
- ◆ Use With BivarOpto SM Series LEDs
- ◆ PLP1 Series Panel Light Pipes Press Into A 0.119 - 0.121" Hole
- ◆ For Added Retention & Contrast, Use C-103-SR (See Page 86)

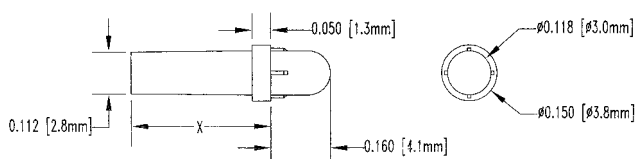

PLP 2

Panel Light Pipe, Low-Profile Round


Color: See Chart

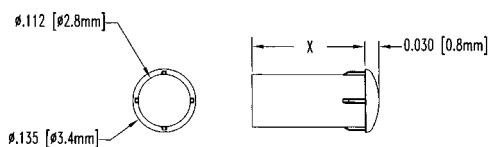

PLP 1-F

Panel Light Pipe, Flat Surface

Color: See Chart

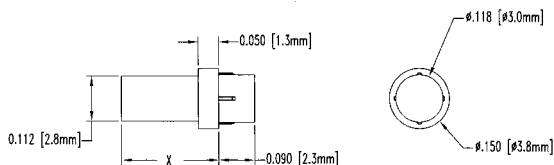


PART NO.

PLP1 Series	PLP2	PLP1-F	X = LENGTH	FACE*	PRICE CODE
PLP1-125	PLP2-125	PLP1-F-125	0.125 (3.2)	F = Flat	E
PLP1-250	PLP2-250	PLP1-F-250	0.250 (6.4)		E
PLP1-350	PLP2-350	PLP1-F-350	0.350 (8.9)		E
PLP1-375	PLP2-375	PLP1-F-375	0.375 (9.5)		E
PLP1-500	PLP2-500	PLP1-F-500	0.500 (12.7)		E
PLP1-625	PLP2-625	PLP1-F-625	0.625 (15.9)		E
PLP1-750	PLP2-750	PLP1-F-750	0.750 (19.0)		E

Colors

XX = Clear unless specified	E
Red = RD	L
Green = GN	L
Blue = BE	L
Yellow = YW	L

EXAMPLES:

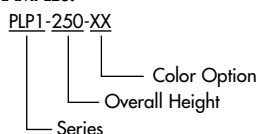

Typical Mounting Information:

Press-fit mounting in 0.119 - 0.121 [3.02mm - 3.07mm] hole
Panel Thickness: 0.047 [1.2mm] to 0.093 [2.4mm]

Material Specifications:

Housing: UL Rated 94V-0, water clear, Polycarbonate
Oxygen Index: +28%
UL file #E121254

