


Tapered roller bearings, single row

Principal dimensions			Basic load ratings		Speed ratings	Limiting speed	Designation
d	D	T	dynamic C	static C0	Reference speed		* SKF Explorer bearing
mm			kN		r/min		-
34,925	72,233	25,4	67,1	90	6700	10000	HM 88649/2/610/2/QCL70

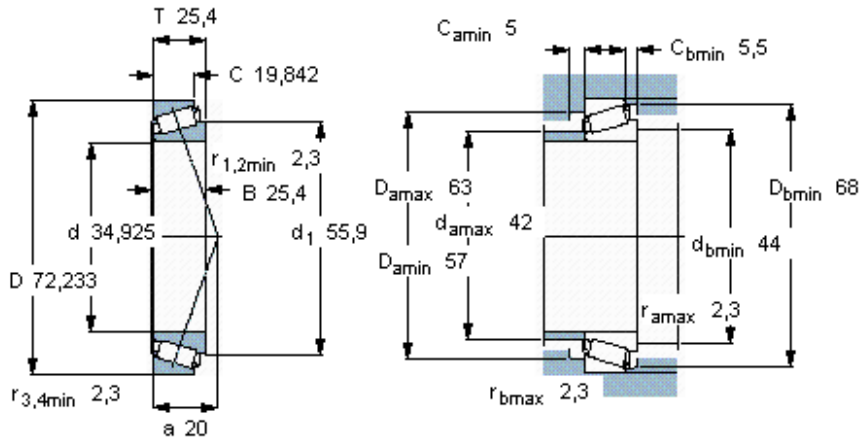

Calculation factors

e 0,54
 Y 1,1
 Y₀ 0,6