


Tapered roller bearings, single row

Principal dimensions			Basic load ratings		Speed ratings	Limiting speed	Designation
d	D	T	dynamic C	static C0	Reference speed		* SKF Explorer bearing
mm			kN		r/min		-
<b>25,4</b>	50,292	14,224	26	30	10000	15000	L 44643/610

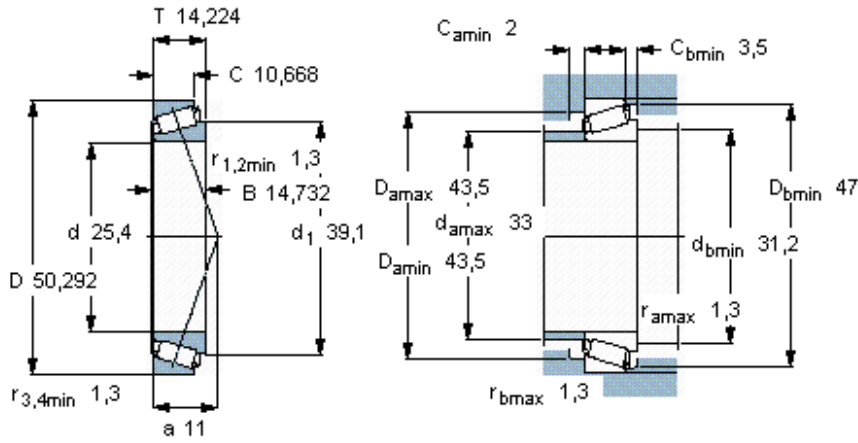

**Calculation factors**

e 0,37  
Y 1,6  
Y<sub>0</sub> 0,9