
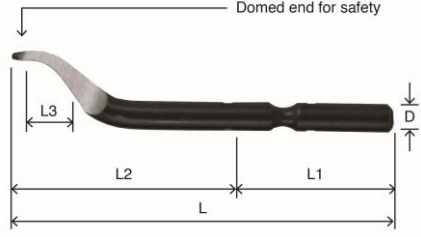


Deburring Blades

S150 Heavy Duty Deburring Blade

	RS Code	339-4819				
	Pack Reference	BK3010				
	Cutting	Right Hand				
	Works best on	For holes 1.5mm and larger				
	Used with Handle	NG-1, NG-3 + S Holder, Plastic Edge Off, Rapid Burr, Plastic Rapid Burr,				
Packed Weight and Dimensions						
Code	Pack Quantity	Weight g	Wmm	Hmm	Lmm	
S150	10	40	65	8	83	

	RS Code	339-4819
	Included Angle	45°
	Blade Material	HSS M2
	Blade Hardness	62 – 64 HRC
	L: Overall Length	44mm
	L1: Length Inside Handle	28mm
	L2: Protrusion from Handle Length	16mm
	L3: Cutting Length	6mm
	D: Shank Diameter	3.2mm