



Fan and Filter Units

IP 43. Can be upgraded by using Sealing Frames and Fine Filter Mats.

Unhindered Air Flow (m ³ /hr.)	Cut-out Dims (mm)	Volts		Part No	Price Each
55	124 x 124	24VDC		SK3322 027	£84.00
		115VAC		SK3322 117	£73.70
		230VAC		SK3322 107	£68.95
105	177 x 177	24VDC		SK3323 027	£106.85
		115VAC		SK3323 117	£86.70
		230VAC		SK3323 107	£81.14
180	224 x 224	24VDC		SK3324 027	£137.09
		115VAC		SK3324 117	£83.10
		230VAC		SK3324 107	£80.96
230	224 x 224	24VDC		SK3325 027	£168.08
		115VAC		SK3325 117	£97.24
		230VAC		SK3325 107	£88.49
500	292 x 292	115VAC		SK3326 117	£124.12
		230VAC		SK3326 107	£113.11

DC versions also available

Outlet Filters


	Cut-out Dims (mm)	Part No	Price Each
	124 x 124	SK3322 207	£19.35
	177 x 177	SK3323 207	£21.76
	224 x 224	SK3325 207	£24.99
	292 x 292	SK3326 207	£26.39

Spare Filter mats

For	Type	Part No	Price Each
SK3322....	Standard	SK3322 700	£8.57
SK3323....	Standard	SK3171 100	£12.43
	Fine	SK3181 100	£12.43
SK3324..../SK3325...	Standard	SK3172 100	£13.52
	Fine	SK3182 100	£13.52
SK3326....	Standard	SK3173 100	£17.12
	Fine	SK3183 100	£17.12

Rack mounted fans

Unhindered Air Flow (m ³ /hr.)	Volts	Part No	Price Each
320	230VAC	SK3340 230	£139.64
480	115-230VAC/24VDC	SK3342 500	£414.97
320	230VAC	SK3144 000	£144.64

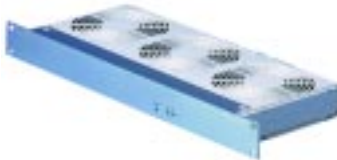



Techline Heat Exchanger



SK3217 100



Heater



Cooling Units

Cooling units

Mounting	Useful Cooling Output W	Volts AC	Part No.	Price Each
Side	300	230	SK3302 100	£644.38
	500	230	SK3303 100	£672.20
	750	230	SK3361 100	£864.86
	1000	230	SK3304 100	£989.22
	1500	230	SK3305 100	£1,439.55
	2000	400	SK3328 140	£1,763.12
Roof	500	230	SK3365 100	£847.42
	750	230	SK3396 100	£941.24
	1500	230	SK3390 100	£1,184.14
	2000	230	SK3385 100	£1,545.19
	2000	400	SK3385 140	£1,761.00

Air-Air Heat Exchangers

Specific thermal Output W/k	Volts AC	Part No.	Price Each
17.5	230	SK3126 100	£410.27
30.0	230	SK3127 100	£503.14
45.0	230	SK3128 100	£649.16
60.0	230	SK3129 100	£768.61
90.0	230	SK3130 100	£914.63

Air-Water Heat Exchangers

Useful cooling Output Watts	Volts AC	Part No.	Price Each
1000	230	SK3217 100	£410.27
3000	230	SK3218 100	£692.21

Heaters and Controls

Heaters

Continuous Thermal Output Watts	Volts	Part No.	Price Each
10	110-240 VAC/DC	SK3105 000	£26.02
20	110-240 VAC/DC	SK3106 000	£28.40
30	110-240 VAC/DC	SK3115 000	£48.24
50	110-240 VAC/DC	SK3116 000	£55.44
* 200	230VAC	SK3107 000	£74.08
* 300	230VAC	SK3102 000	£125.58

* Output with fan SK 3108.000

Axial Fan

Description	Volts AC	Part No.	Price Each
Axial Fan	230	SK3108 000	£40.74

Controls

Type	Volts	Part No.	Price Each
Thermostat	24-230VAC/24-60VDC	SK3110 000	£18.19
Hygrostat	24-230VAC/DC	SK3118 000	£59.05

SAREL



Fan & Filter units




Outlet Grills



Heater



Thermostat

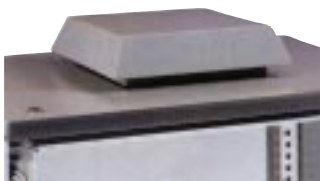

Natural ventilation device



Metal ventilation louvres



Plastic ventilation louvres

Fan and Filter units

Unhindered Air Flow (m3/hr.)	Cut-out Dims (mm)	Volts AC	Part No.	Price Each
38	92 X 92	115	ENN87606	£66.57
88	125 X 125	115	ENN87608	£81.05
165	125 X 125	115	ENN87583	£96.58
300	125 X 125	115	ENN87584	£166.40
560	223 X 223	115	ENN87585	£144.82
850	223 X 223	115	ENN87586	£157.05
38	291 X 291	230	ENN87600	£58.53
85	291 X 291	230	ENN87601	£69.62
165	291 X 291	230	ENN87602	£75.13
300	291 X 291	230	ENN87602	£89.11
560	291 X 291	230	ENN87604	£113.02
850	291 X 291	230	ENN87605	£134.02

DC Filter Fans and Reverse Flow Fans also available

Outlet Grills

Cut-out Dims (mm)	Part No	Price Each
92 X 92	ENN87610	£13.43
125 X 125	ENN87611	£17.67
223 X 223	ENN87612	£20.07
291 X 291	ENN87613	£23.29

Heaters and Controls

Heaters

Type	Watts	Volts AC	Part No	Price Each
Heater only	10	110-230	ENN17501	£23.34
	20	110-230	ENN17502	£29.11
	55	110-230	ENN17506	£51.75
	90	110-230	ENN17509	£63.43
	150	110-230	ENN17515	£69.36
	250	230	ENN17531	£110.25
500	230	ENN17526	£156.97	

Controls

Type	Contact Type	Rating 230V Resistive	Max Volts AC	Part No	Price Each
Thermostat	NC	2	250	ENN87561	£15.72
	NO	2	250	ENN87562	£15.72
Electronic Thermostat	24V°C 2 dry contact			ENN87563	£38.16
Dual Thermostat	°C			ENN87564	£28.84
Prefixed Thermostat	5°C/41°F	NC	230	ENN87565	£14.93
	10°C/50°F	NC	230	ENN87566	£14.93
	15°C/59°F	NC	230	ENN87567	£14.93
	25°C/77°F	NO	230	ENN87568	£14.93
	30°C/86°F	NO	230	ENN87569	£14.93
	35°C/95°F	NO	230	ENN87570	£14.93
Dual Prefixed Thermostat	NC 10°C/50°F			ENN87571	£27.40
	NO 35°C/95°F				
	NO 35°C/95°F			ENN87572	£27.40
	NO 45°C/113°F				
Dual Prefixed Thermostat	NC 5°C/41°F			ENN87573	£27.40
	NC 15°C/59°F				
Prefixed Hygrostat	60% RH Reverser			ENN87574	£141.27
Thermostat	NC			ENN87578	£19.08
	NO			ENN87580	£19.08

Natural ventilation & circulation

Type	Part No	Price Each
Natural Ventilation Device	ENN21306	£120.14
Top Stand-offs (Pack of 4) ♦	ENN21307	£20.64

♦ Only applicable to spacial 6000 enclosures.

Ventilation Louvres

Type	Description	Part No	Price Each
Metal	70mm (120 x 120) Louvre Length	ENN21407	£1.97
	100mm (160 x 160) Louvre Length	ENN21410	£2.60
	180mm (220 x 220) Louvre Length	ENN21418	£5.11
Plastic	35mm Drilling Dia. 2 ventilation louvres IP44	ENN21412	£2.20