




**126A.50** 126A - Hinged hook and pin wrenches

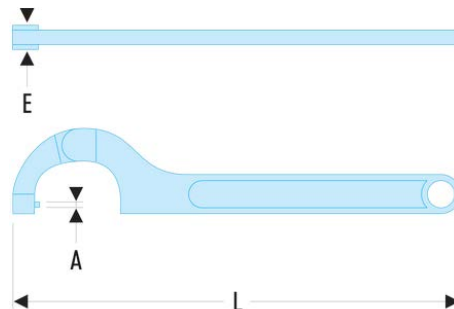

- For nuts with lateral holes.
- Removable hooks.
- Same design and benefits as the "125A" wrench, but fitted with removable hooks to turn holed nuts.
- The 5 dimensions replace more wrenches than all classical fixed models.
- Hooks treated for high hardness.
- Capacity: 15 to 180 mm.
- Presentation: satin chrome finish.

A [mm]: 4

d [mm]: 35 - 50

E [mm]: 12

E maxi [mm]: 12

L [mm]: 202

[g]: 170