

SureColor SC-P800

# DISCOVER THE NEW BLACK



**EPSON**<sup>®</sup>  
EXCEED YOUR VISION

# TECHNICAL INFORMATION

## VERSATILE MEDIA PRINTS

---

The SureColor SC-P800 is the first ever A2 printer with an optional roll paper unit. It's capable of printing on a wide variety of media and gets great results on glossy, matte, fine art and photo paper, as well as canvas.



## SUPERIOR QUALITY A2+ PRINTS

---

Take advantage of the optional roll-feed capability to print panoramic images up to 17" width. The built-in front loading paper feed enables A2+ printing on a wide variety of photo, fine art papers and thick media.



## SUPER CONNECTIVITY

---

Its powerful wireless interface means you're no longer bound by cords, cables and wires. Now you can make the most of connecting to your printer from anywhere, all from your smartphone, tablet or PC – giving you even more flexibility and freedom while you work.

The automatic Wi-Fi set up makes connectivity a breeze. Epson Connect, Apple AirPrint, Google Cloud Print are also supported.



## BIG ON PERFORMANCE, SMALL ON FOOTPRINT

---

Measuring just 684 x 376 x 250 mm, the SC-P800's elegant design is sure to fit in with any workspace, studio or home, without compromising on performance.

## CONTROL EVERYTHING AT YOUR FINGERTIPS

---

Operating the printer couldn't be easier. With a large 2.7-inch colour touch control panel, it's easy to see and check the printer status at a glance.






**EPSON ULTRACHROME**  
**HD** INK



# STRIKING, DRAMATIC COLOURS

## BREATHE COLOUR INTO YOUR PRINTS

Create prints that truly capture the intensity of the moment with the SureColor SC-P800. Superior nine-colour UltraChrome HD and vivid magenta inks produce an exceptionally wide colour gamut and outstanding smooth tones – resulting in higher quality images across a wide variety of media. Durable resin-coated pigment ink delivers superb longevity and colour control so you can create stunning prints that will last for years.

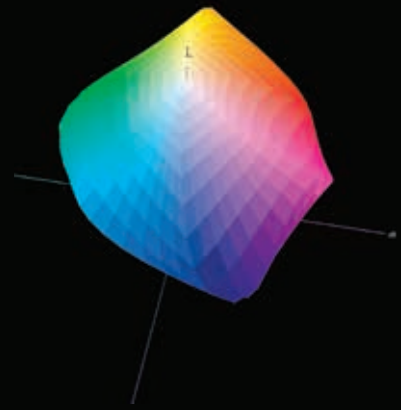


Exceptionally wide colour gamut and the highest black density on the market.<sup>3</sup>

## REDUCED BRONZING

Bronzing on glossy paper simply isn't a problem with UltraChrome HD Ink. It forms a thicker layer on the media surface, reducing the difference between colours such as magenta and cyan, that can often be a cause of bronzing.

### UltraChrome K3 Ink

Media surface

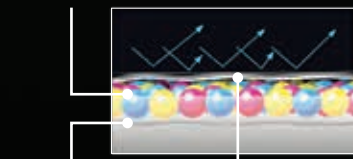


Paper section

Resin


### UltraChrome HD Ink

Media surface

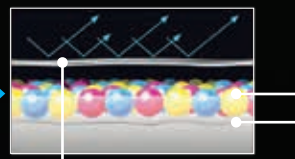

Paper section

Resin

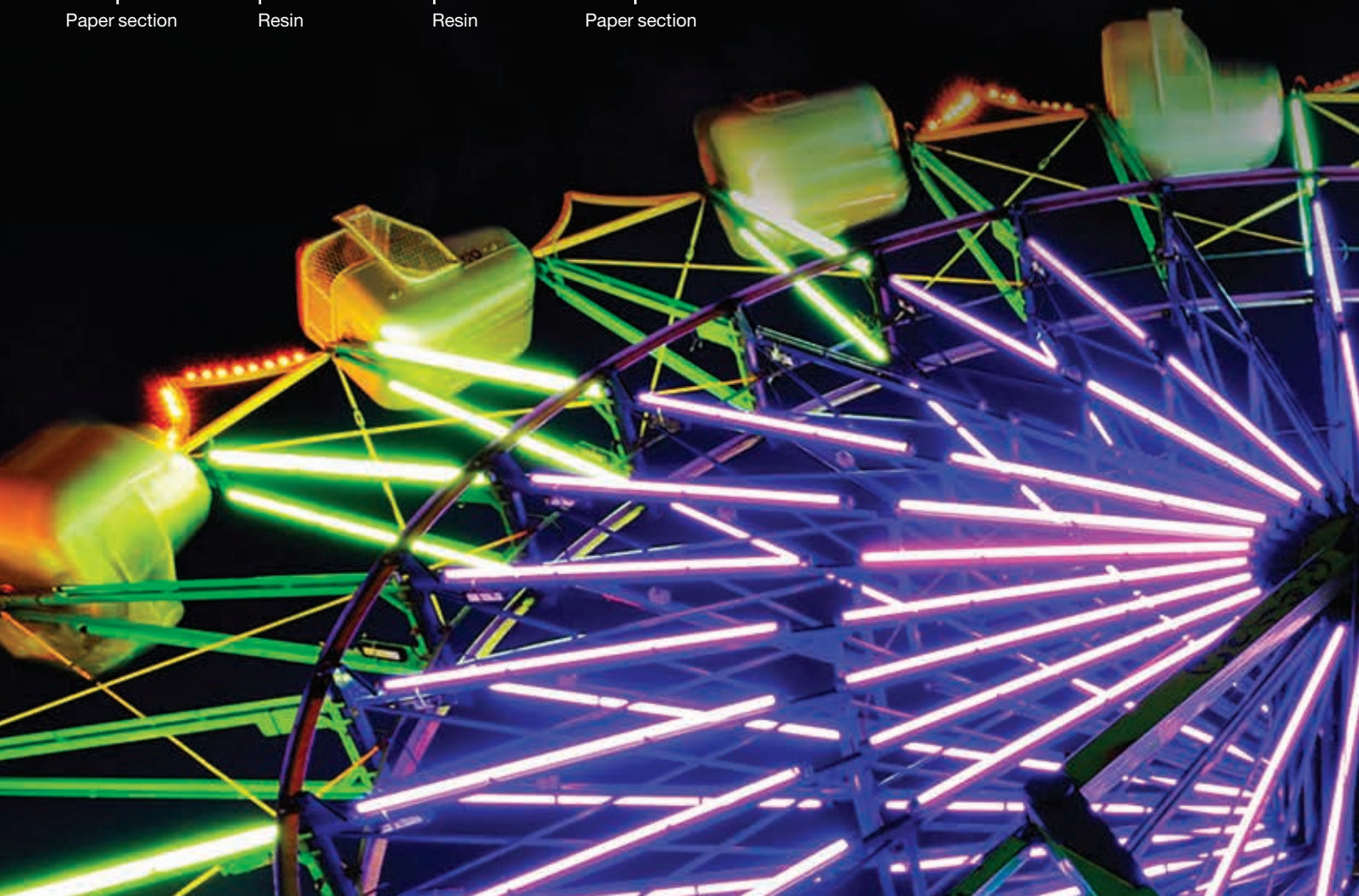

# CAPTURE THE BLACKEST BLACKS

Discover the deepest blacks<sup>3</sup> with SureColor SC-P800's ultra-rich black density capabilities. Create prints with the richest blacks and ultra-smooth tonal gradation with the industry's highest density black printer at your fingertips (2.86DMax on premium glossy photo paper).

The SureColor SC-P800 offers new possibilities for photography and print professionals when printing in black and white. The three level black ink technology achieves a significantly more stable and accurate grey balance, giving you more colour control and higher quality black and white prints.





# LONGER-LASTING PRINTS WITH GREATER PRECISION

## **SUPERIOR, LONGER-LASTING PRINTS**

---

There's no need to compromise the longevity of your prints when you need to showcase your greatest work. With a high pigment density and expanded colour gamut, you get a bold, accurate and intense colour output that you know will be enjoyed for years to come.

## **RAZOR-SHARP PRINTS, EVERY TIME**

---

Capture every last detail on your images thanks to Epson's MicroPiezo printhead. Exceptionally precise dot placement, and the ability to produce droplets as small as 3.5pl, ensures high-quality, high-speed printing – every time.



# BUILT FOR SPEED, WITHOUT COMPROMISING ON QUALITY

This printer will keep up with your busy printing schedule. It outputs an A3+ (323 x 477mm) print in 270 seconds, and gives you the ability to print a range of sizes (up to A2+) on a wide variety of photo and fine art papers, canvas and thick media.



# SPECIFICATIONS

<b>Product name</b>	SureColor SC-P800
<b>Maximum print size</b>	17in wide
<b>Ink technology</b>	Epson UltraChrome® HD
<b>Printing technology</b>	Epson Micro Piezo™ printhead
<b>Nozzle configuration</b>	180 nozzles black, 180 nozzles per colour (Vivid Magenta, Cyan, Photo Black/ Matte Black, Yellow, Light Light Black, Light Black, Light Cyan, Vivid Light Magenta)
<b>Maximum print resolution</b>	2880 x 1440dpi
<b>Minimum dot size</b>	3.5pl with Variable-Sized Droplet Technology
<b>Interfaces</b>	USB, Ethernet, Wi-Fi
<b>Paper handling</b>	Auto sheet feeder, borderless print, fine art paper path, manual duplex, roll paper <sup>1</sup> , thick media support
<b>Paper support</b> Paper size	A2, A3+, A3++, A3, A4, A5, A6, B3, B4, B5, B6, C4 (envelope), C5 (envelope), C6 (envelope), letter, letter legal, 10 x 15cm, 13 x 18cm, 13 x 20cm, 20 x 25cm, 100 x 148mm, 17in (43.2cm), user defined
Thickness (ASF)	0.08mm-0.11mm
Thickness (Front Thick Paper Path)	0.29mm-0.70mm 1.20mm-1.50mm
<b>Control panel</b>	2.7in colour LCD touch screen
<b>Utility software</b>	EpsonNet Config, EpsonNet Setup, EpsonNet Print, Epson Print Layout, ColorBase2, iPrint
<b>Dimensions (W x D x H in mm)</b> Storage	684 x 376 x 250mm
Printing	684 x 963 x 550mm
<b>Weight</b>	Approx. 19.5kg (main unit only)
<b>Noise level</b> Sound pressure level (LpAm)	49.6 (A) according to ISO 7779 pattern with Epson premium glossy photo paper/ photo RPM mode
<b>Power consumption</b>	1.8W (sleep mode), 21W (printing), 0.5W (Power off), ENERGY STAR® qualified
<b>Temperature</b>	10-35°C (operating), -20-40°C (storage)
<b>Humidity</b>	20-80% No condensation (operating), 5-85% No condensation (storage)

## ROLL PAPER UNIT

<b>Core</b>	2in for Canvas media 3in for the other media
<b>Print width</b>	13in-17in
<b>Print length</b>	Guaranteed: 55mm – 1.1m (44in) Max. Not guaranteed: up to 3.3m
<b>Dimensions (W x D x H in mm)</b> Roll paper unit (excluding spindles)	564 x 227 x 277 mm
Roll paper unit with main unit (including a spindle)	684 x 586 x 286 mm
<b>Supported media</b>	Canvas Satin, Canvas Gloss, Canvas Matte, Cold Press Bright, Cold Press Natural, Enhanced Matte Paper <sup>2</sup> , Hot Press Bright, Hot Press Natural, Premium Glossy Photo Paper (250), Premium Semigloss Photo Paper (250), Premium Luster Photo Paper (250), Premium Semimatte Photo Paper (260), Traditional Photo Paper, Ultra Smooth Fine Art Paper (250) <sup>2</sup>

<sup>1</sup> Optional <sup>2</sup> 2880x1440 is not available on matte media <sup>3</sup> Compared against competitors' A2 photo printers with a 6-colour or greater ink-set available as of January 2015

  
Better Products  
for a Better Future

For further information please contact your local Epson office or visit [www.epson.co.uk](http://www.epson.co.uk)

Telephone: 01952 607111 (UK)\*  
01 436 7742 (Republic of Ireland)  
E-mail: [enquiries@epson.co.uk](mailto:enquiries@epson.co.uk)  
Chat: [etalk.epson-europe.com](http://etalk.epson-europe.com)  
Fax: 0871 222 6740

Web: [www.epson.co.uk](http://www.epson.co.uk)  
[www.epson.ie](http://www.epson.ie)

\* Local call rate.

Trademarks and registered trademarks are the property of Seiko Epson Corporation or their respective owners. Product information is subject to change without prior notice. All images are for illustrative purposes only.

**EPSON®**