


Datasheet

Stock No: [798-3438](#)

**RS Pro Temperature Probe, PTC, -19.9 → +150 °C**

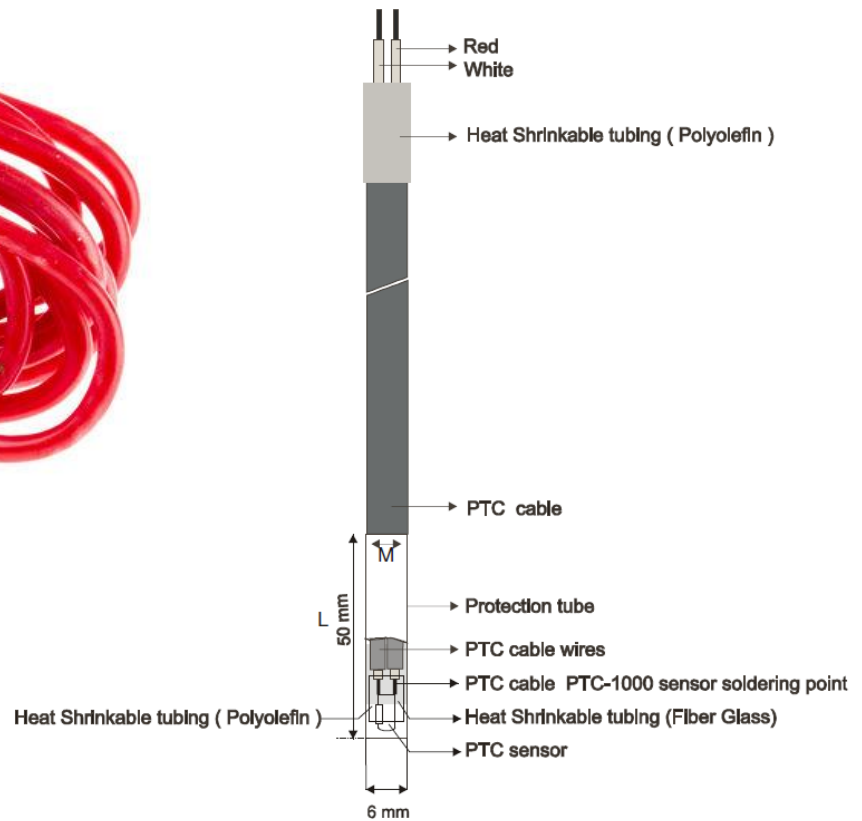

**Specifications:**

Sensor Type:	PTC
Probe Type:	Air
Protection Tube Material:	Nickel coated brass
Minimum Temperature Measurement:	-50°C
Maximum Temperature Measurement:	+150°C
Length:	40 mm
Diameter (Internal):	3.5 mm
Diameter (External):	6 mm
Cable Length:	1.5 m
Best Accuracy:	±1%