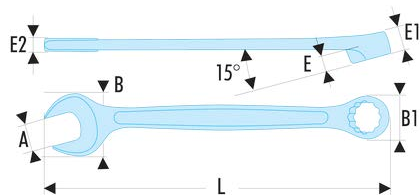
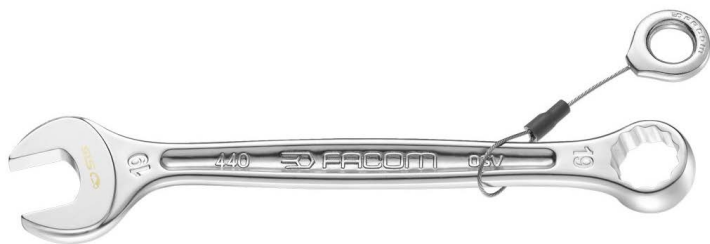


440.19SLS 440.SLS - Metric combination wrenches**Description :**

- Tool equipped with a FACOM SLS attachment solution, preventing any risk of accidental falls.
- The crimped "sliding" cable solution, selected and tested by FACOM, maintains user ergonomics (8 - 30 mm wrenches).
- Standard wrench for all current applications.
- High mechanical strength combined with compact size meeting aeronautical standards.
- Ring head:
 - Ring open end (size E) designed for better access to series or embedded screws.
 - OGV® profile with 12-point ring for powerful tightening while protecting the nut.
 - Ring head angled at 15°.
- Open end head:
 - Open end angled at 15°.
 - Open end head-handle geometry optimised for increased access.
- Metric sizes: 6 to 34 mm.
- Presentation: satin chrome finish.

A [mm]: 19

B [mm]: 41,2

B1 [mm]: 27,8

C1 [mm]: 11,9

E [mm]: 7,2

E1 [mm]: 11,9

E2 [mm]: 8,3

L [mm]: 216

[g]: 195
