


180.CPESLS High-performance multigrip pliers -SLS

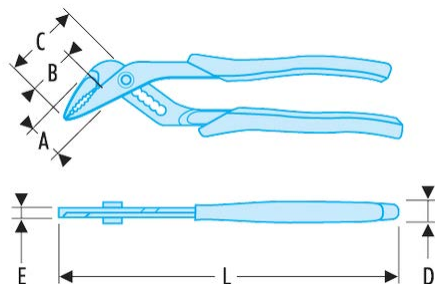

Description :

- Tool equipped with a FACOM SLS attachment solution, preventing any risk of accidental falls.
- The crimped "rotating" cable solution, selected and tested by FACOM, maintains user ergonomics.
- Capacity: 44 mm.
- Ideal for confined spaces: long reach thin noses.
- Double heat-treated tips: high wear resistance, hardness 60/62 HRc.
- 3 options:
 - Chrome finish, ergonomic grips.

A [mm]: 27

B [mm]: 34

E [mm]: 8

E1 [mm]: 22

L [mm]: 250

L1 [mm]: 58

[g]: 385
