


Flexible Coaxial Cable Assembly RG59 - BNC Straight Plug / BNC Straight Plug 114-2626-xxxxA

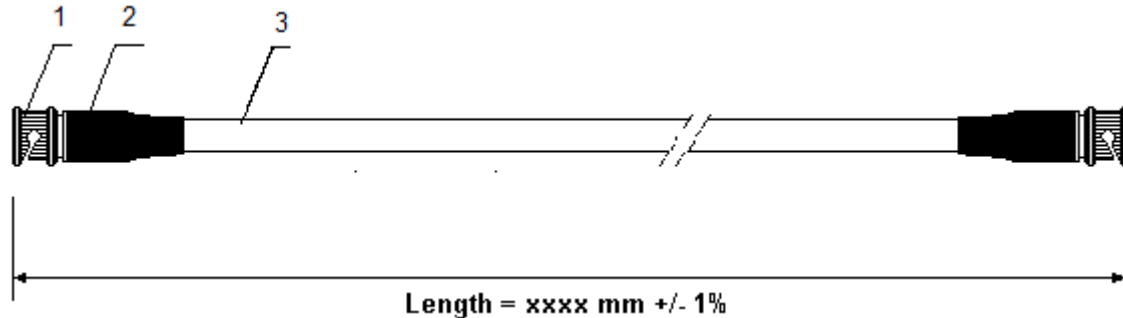

List Nomenclature

- | | |
|--------------------------------------|------------------|
| 1. BNC straight plug brass connector | A04050 |
| 2. Black Protective sleeve | A20008 |
| 3. Coaxial Cable | A90043 (RG59B/U) |

Electrical Specifications

Impedance	:	75 ± 2 Ohms
Operating Frequency	:	DC to 1 GHz
Velocity of Propagation	:	66%
Voltage Withstand	:	1000 Veff

Mechanical Specifications

Inner Conductor	:	Solid SC	
Dielectric	:	PE	
Braid	:	Cu 77% recovering	
Jacket	:	PVC	Ø = 6,15 mm (0,242 inches)
Static Bend Radius	:	21,60mm (0,850 inches)	

Environmental Specifications

Operating Temperature Range	:	-10°C à +70°C
-----------------------------	---	---------------

Conditions of delivery

Mechanical check	:	Length
Electrical test	:	Continuity / Rigidity