


F3MX

Male Connector – BSPT
37° Flare / BSPT

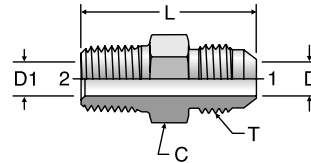

TUBE FITTING PART #	END SIZE		T TUBE END UN/UNF-2A	C HEX (mm)	D (mm)	D1 (mm)	L (mm)	Dynamic Pressure (x 1,000 PSI)			
	1	2						-S	-SS	-B	
	(mm)	(in.)									BSPT
4F3MX	6	1/4	1/8 - 28	7/16 - 20	13	4.4	4.4	30.7	4.5	4.5	2.9
4-4F3MX	6	1/4	1/4 - 19	7/16 - 20	14	4.4	4.4	35.3	4.5	4.5	2.9
5F3MX	8	5/16	1/8 - 28	1/2 - 20	14	6.0	4.8	30.7	4.5	4.5	2.9
5-4F3MX	8	5/16	1/4 - 19	1/2 - 20	14	6.0	6.0	35.3	4.5	4.5	2.9
6F3MX	10	3/8	1/4 - 19	9/16 - 18	17	7.5	7.5	35.6	4.5	4.5	2.9
6-6F3MX	10	3/8	3/8 - 19	9/16 - 18	19	7.5	7.5	36.4	4.5	4.5	2.9
6-8F3MX	10	3/8	1/2 - 14	3/4 - 16	22	7.5	7.5	42.9	4.5	4.5	2.9
8-4F3MX	12	1/2	1/4 - 19	3/4 - 16	19	9.9	7.0	38.1	4.5	4.5	2.9
8F3MX	12	1/2	3/8 - 19	3/4 - 16	19	9.9	9.9	38.9	4.5	4.5	2.9
8-8F3MX	12	1/2	1/2 - 14	3/4 - 16	22	9.9	9.9	45.5	4.5	4.5	2.9
10-6F3MX	14, 15, 16	5/8	3/8 - 19	7/8 - 14	24	12.3	10.3	43.2	4.5	4.5	2.9
10F3MX	14, 15, 16	5/8	1/2 - 14	7/8 - 14	24	12.3	12.3	48.0	4.5	4.5	2.9
10-12F3MX	14, 15, 16	5/8	3/4 - 14	7/8 - 14	27	12.3	12.3	48.3	2.3	2.3	1.5
12-8F3MX	18, 20	3/4	1/2 - 14	1 1/16 - 12	27	15.5	13.5	50.8	4.5	4.5	2.9
12F3MX	18, 20	3/4	3/4 - 14	1 1/16 - 12	27	15.5	15.5	50.8	2.3	2.3	1.5
12-16F3MX	18, 20	3/4	1 - 11	1 1/16 - 12	36	15.5	15.5	57.1	2.3	2.3	1.5
16-12F3MX	25	1	3/4 - 14	1 5/16 - 12	36	21.5	18.0	53.6	2.3	2.3	1.5
16F3MX	25	1	1 - 11	1 5/16 - 12	36	21.5	21.5	58.5	2.3	2.3	1.5
20-16F3MX	30, 32	1 1/4	1 - 11	1 5/8 - 12	46	27.5	23.8	61.4	2.3	2.3	1.5
20F3MX	30, 32	1 1/4	1 1/4 - 11	1 5/8 - 12	46	27.5	27.5	62.2	2.3	2.3	1.5
24F3MX	38	1 1/4	1 1/2 - 11	1 7/8 - 12	50	33.0	33.0	68.1	2.3	2.0	1.3

Dimensions and pressures for reference only, subject to change.