

AUXILIARY SWITCH BLOCK, DIN EN 50005,
2NO+2NC, CAGE CLAMP,
F.CONTACTOR RELAYS A. CONTACT. F. SWITCHING
MOTORS, SIZE S0...S12



Auxiliary circuit:

Number of NC contacts / for auxiliary contacts

- instantaneous switching

2

Number of NO contacts / for auxiliary contacts

- instantaneous switching

2

Operating current / of the auxiliary contacts / at AC-15

- at 230 V

A

6

Installation/mounting/dimensions:

Type of mounting

snap-on mounting

Connections:

Design of the electrical connection

- for auxiliary and control current circuit

spring-loaded terminals

Certificates/approvals:

General Product Approval

**Functional Safety /
Safety of
Machinery**

**Declaration of
Conformity**



CCC



CSA



GOST



UL

[Type Examination](#)



EG-Konf.

Test Certificates

[Special Test
Certificate](#)

[Type Test
Certificates/Test
Report](#)

Shipping Approval



ABS



BUREAU
VERITAS



GL



LRS



RINA



RMRS

other

[Environmental
Confirmations](#)

Further information:

Information- and Downloadcenter (Catalogs, Brochures,...)

<http://www.siemens.com/industrial-controls/catalogs>

Industry Mall (Online ordering system)

<http://www.siemens.com/industrial-controls/mall>

Cax online generator:



<http://www.siemens.com/cax>

Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<http://support.automation.siemens.com/WWW/view/en/3RH1921-2FA22/all>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)

http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=3RH1921-2FA22

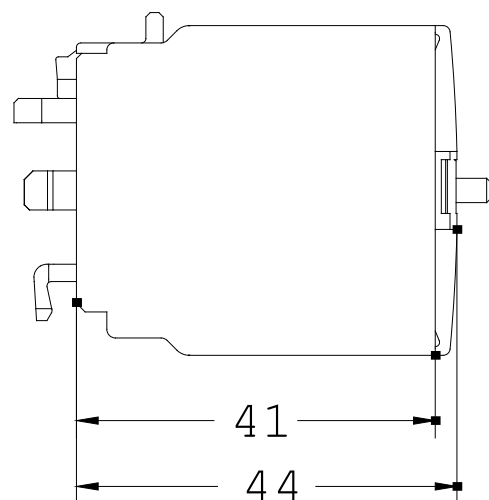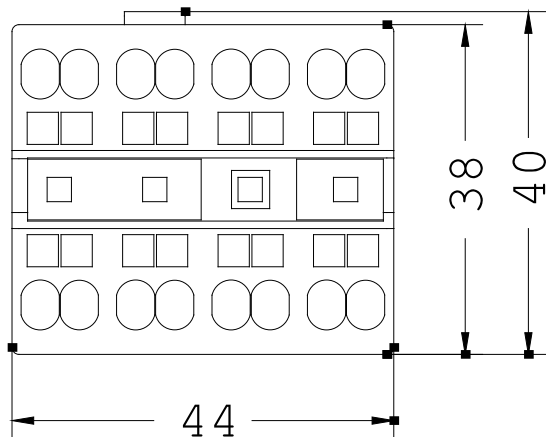

last change:

Sep 10, 2012