



ENGLISH

Datasheet

Stock No: 123-7962

RS Pro MR16 Glass GU5.3 5W (37W) 4000K 450lm Non-Dimmable Lamp - 3 PACK



Specifications:

Lamp Base: MR16 GU5.3

Lamp Shape: Round

Wattage: 5W

Voltage Rating: 12V

Length: 44mm

Diameter: 50mm

Current Rating: 580mA

Frequency Range: 50Hz

Electric Current: AC

Features:


The Base Colour is transparent Glass. Made with aluminium and glass.



ENGLISH

Heat Graph: Cool

4000 K

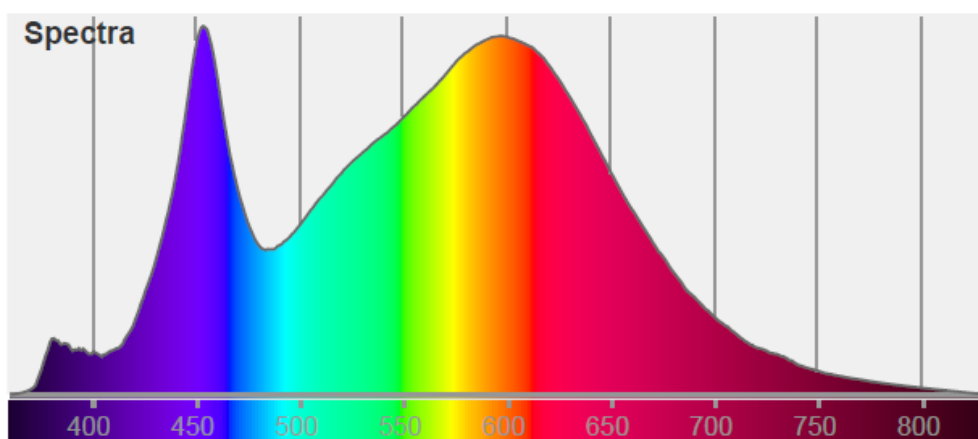

Beam Angle: 36 Degrees

Beam angle

36°

