


DATA SHEET:

GU5WW, GU5CW, GU5DL

Knightsbridge[®]
the mark of quality

ISSUE: BASEP16VOL3

5W GU10 LED

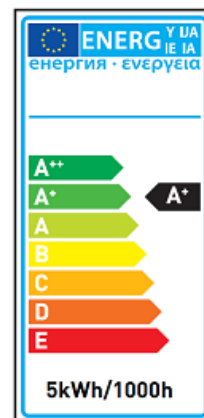

*Image shows GU5WW

MLA part code	GU5WW	GU5CW	GU5DL
Description	GU10 LED lamp		
Finish	Clear		
Nett weight (kg)	0.05	0.05	0.066
Wattage (W)	5		
Lamp Base	GU10		
Lumens (lm)	420	470	400
Efficacy (lm/W)	78	88	80
CCT	2700K	4000K	6000K
LED colour	Warm white	Cool white	Daylight
CRI	>80		
Overall dimensions (mm)	Diameter: 50 Height: 53		
Beam angle (°)	38		
P.F	0.58	0.57	0.69
Operating current (A)	0.039	0.040	0.032
Input voltage	Mains 230V 50Hz		
Construction body	Glass		
Life span (Hrs)	25,000		
Warranty	2 Years		
Dimmable	No		
Origin of Manufacture	China		
Declaration of Conformity (held on file)	Yes		
Manufactured in accordance with	EN 60432		
EAN	5055832950189	5055832950271	5055832956624

