


Datasheet

Insulated Crimp Spade Connector

RS Stock number [534-272](#)

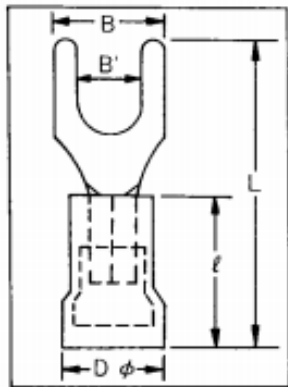

| Insulated | Wire range | | Dimensions(mm) | | | | Stud size | | |
|-----------|------------|-----------------|----------------|-----|-----|------|-----------|-----|-----|
| Stock no. | AWG | mm ² | Colour | B | D φ | L | r | AWG | mm |
| 2082515 | 22-16 | 0.5-1.5 | Red | 5.7 | 4.3 | 20.5 | 9.9 | 4 | 3.2 |
| 534272 | 22-16 | 0.5-1.5 | Red | 6.4 | 4.3 | 20.0 | 9.9 | 6 | 3.7 |
| 534266 | 22-16 | 0.5-1.5 | Red | 6.4 | 4.3 | 20.5 | 9.9 | 8 | 4.3 |
| 534250 | 22-16 | 0.5-1.5 | Red | 8.5 | 4.3 | 25.0 | 9.9 | 10 | 5.3 |

| Stock no. | AWG | mm ² | Colour | B | D φ | L | r | AWG | mm |
|-----------|-------|-----------------|--------|-----|-----|------|-----|-----|-----|
| 534632 | 16-14 | 1.5-2.5 | Blue | 6.4 | 4.8 | 20.5 | 9.9 | 6 | 3.7 |
| 534626 | 16-14 | 1.5-2.5 | Blue | 6.4 | 4.8 | 20.5 | 9.9 | 8 | 4.3 |
| 534610 | 16-14 | 1.5-2.5 | Blue | 8.5 | 4.8 | 20.5 | 9.9 | 10 | 5.3 |

| Stock no. | AWG | mm ² | Colour | B | D φ | L | r | AWG | mm |
|-----------|-------|-----------------|--------|-----|-----|------|------|-----|-----|
| 534503 | 12-10 | 2.5-6.0 | Yellow | 6.4 | 6.5 | 25.5 | 13.5 | 6 | 3.7 |