

## Datasheet

# 140 mm Steel Flat Nose Pliers

RS Stock number [606-535](#)




### Description

- Strong pressed steel frame
- Riveted lap joint
- Precision ground 3mm jaw
- Ribbed soft plastic grips and lightweight return spring
- Integral stop

### Specifications


- |                    |       |
|--------------------|-------|
| • Cutting Capacity | 3mm   |
| • Material         | Steel |
| • Overall Length   | 140mm |
| • Weight           | 78g   |

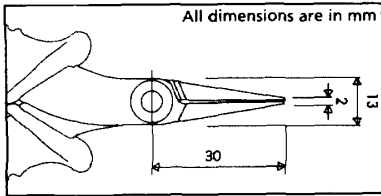

**FLAT NOSE PLIER**

**P10**



- Precision nose plier with serrated jaws
- Jaw width 3mm
- Length 140mm

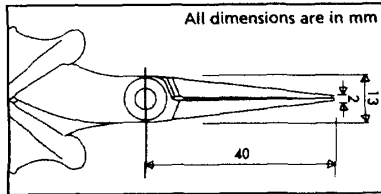

**LONG NEEDLE NOSE PLIER**

**P11**


 
- Long-needle nose plier with serrated jaws
- Tapered jaw to 1.2mm width
- Length 152mm

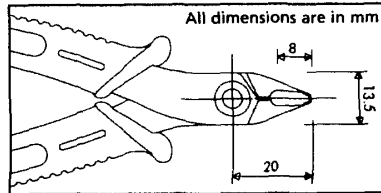

**FLUSH CUTTER**

**P13**



- Max wire  $\varnothing$  16 AWG/.051" (1.3mm) soft wire
- Cutting angle 21°
- Length 132mm
- Safety clip available. Add "-A" to Part No.

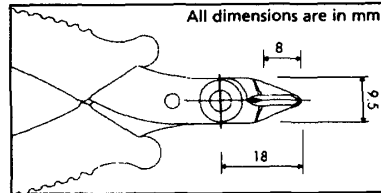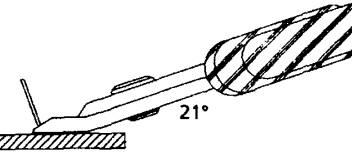

**LIGHTWEIGHT FLUSH CUTTER**

**P13-LW**



- Max wire  $\varnothing$  16 AWG/.051" (1.3mm) soft wire
- Cutting angle 21°
- Lightweight 1.6oz (45g)
- Length 125mm
- Safety clip available. Add "-A" to Part No.

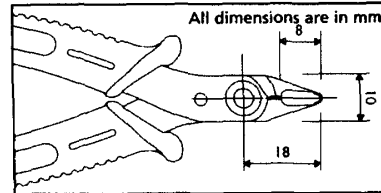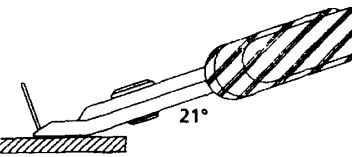

**ANGLED FLUSH CUTTER**

**P14**



- Max wire  $\varnothing$  16 AWG/.051" (1.3mm) soft wire
- Cutting angle 21°
- Length 130mm
- Safety clip available. Add "-A" to Part No.

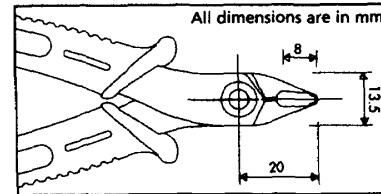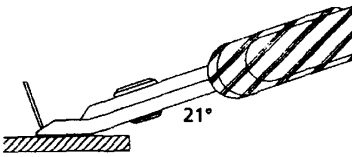

**FLUSH CUTTER**

**P15**



- Max wire  $\varnothing$  16AWG/.051" (1.3mm)
- Cutting angle 48°
- Length 130mm

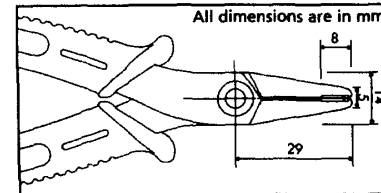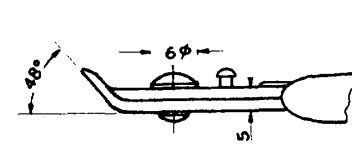

**ANGLED HEAD CUTTER**

**P17**



- Max wire  $\varnothing$  18 AWG/.040" (1.0mm)
- Cutting angle 30°
- Length 140mm

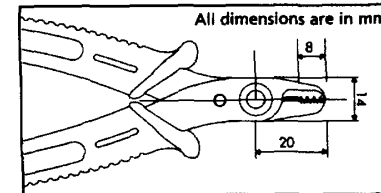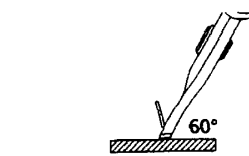

**WIRE STRIPPER**

**P21**

- Max wire  $\varnothing$  28-24 AWG/.012"-.020" (0.3-0.5mm)
- Length 132mm

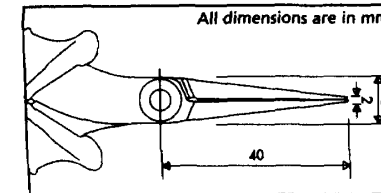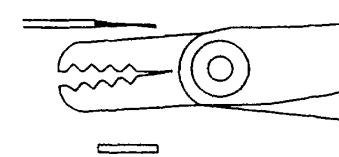

**LONG FLAT NOSE PLIER**

**P24**

- Long flat nose plier with serrated jaws.
- Jaw width 3mm
- Length 152mm

