


Datasheet

RS Pro Standard DIN Rail Terminal, 0.2 to 2.5mm², 24A, Red

RS Stock No: **501-821**

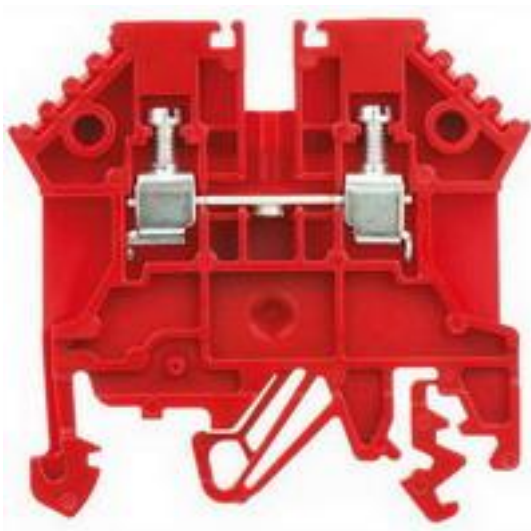

Product Details

RS Pro standard DIN rail terminal in red colour, identifies signals or voltages easily. It has a current rating of 24 A and supports wire size of 0.2 to 2.5 mm². The DIN rail terminal meets UL, NEMKO, GOST and CSA standards.

Features and Benefits

- Identify signals or voltages easily
- Terminal colours match incoming cables, reducing wiring error
- Three phase systems are always wired consistently

Specifications:

Cable CSA	0.2 to 2.5 mm ²
Colour	Red
Current Rating	24 A
Maximum Operating Temperature	+105°C
Minimum Operating Temperature	-40°C
Number of Levels	Single
Voltage Rating	800 V
Wire Size	0.2 to 2.5 mm ²
Dimensions	48 x 5 x 47 mm
Standards Met	UL, CSA, NEMKO, GOST

Suitable terminals for RS 399105	RS Part No	Description
		10 pole cross connector
	802777	2.5mm Terminal Beige
	802783	2.5mm Terminal Blue
	501635	2.5mm din rail terminal brown
	501730	2.5mm din rail terminal orange
	501976	2.5mm din rail terminal black
	501639	2.5mm din rail terminal grey
	501613	2.5mm din rail terminal white
	501641	2.5mm din rail terminal yellow
	501821	2.5mm din rail terminal red