

Datasheet

RS 2 Core Multicore Speaker Cable, PVC Insulation 60 V

Stock number: 714-0300



Product Description

Reference Standard

Customer's sample spec.and the general standard


Multi-construction

Cable Construction

Conductor	Bare Copper
Construction	0.25±0.008×7
Standard Dia.(mm)	0.76
Insulation	PVC
Thickness	0.5
Insulation Dia.(±0.1mm)	1.8×2
Insulation Color	Brown
Marking	One Black Stripe on one leg of Twin
Print Marking	
2 core 7/0.25mm 60 V PVC [MM][WkYr]	

PACKAGING

100M/Cardboard Reel.

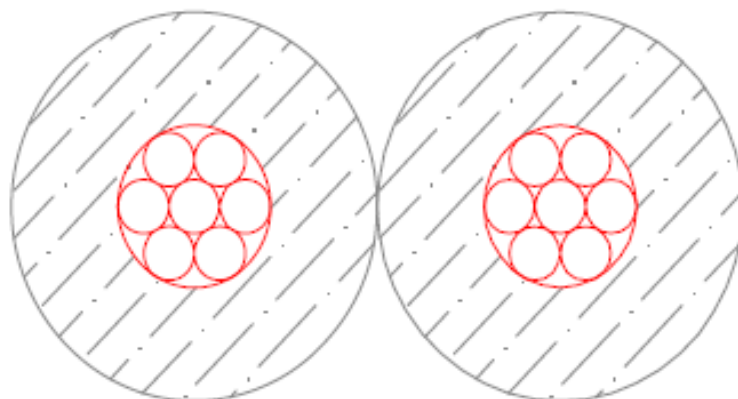

Electrical Characteristics

Max.Conductor DC Resistance at 20 °C (Ω /Km)	<55.2
Min.Insulation DC Resistance at 20 °C (M Ω *Km)	200
Rated Temperature(°C)	80
Rated Voltage (V)	60