

## Datasheet

# RS 2 Core Multicore Speaker Cable, PVC Insulation 60 V

Stock number: 714-0307



### Product Description

#### Reference Standard

Customer's sample spec.and the general standard

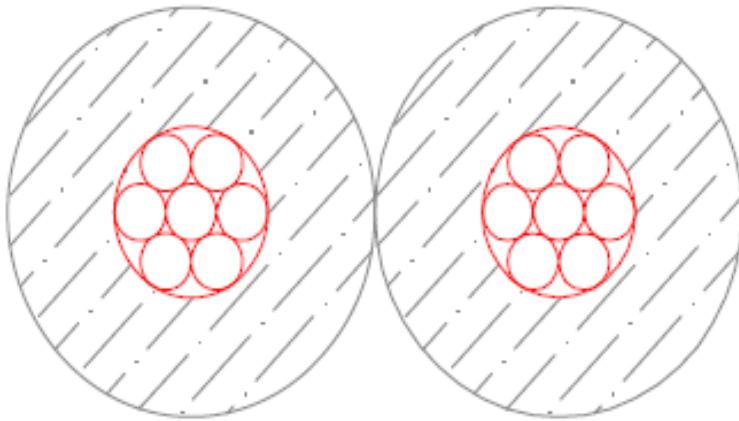
#### Multi-construction

### Cable Construction

<b>Conductor</b>	<b>Bare Copper</b>
Construction	0.25±0.008×7
Standard Dia.(mm)	0.76
<b>Insulation</b>	<b>PVC</b>
Thickness	0.5
Insulation Dia.(±0.1mm)	1.8×2
Insulation Color	Black
Marking	One White Stripe on one leg of Twin
<b>Print Marking</b>	
2 core 7/0.25mm 60 V PVC [MM][WkYr]	

#### PACKAGING

100M/Cardboard Reel.

**Electrical Characteristics**

Max.Conductor DC Resistance at 20 °C ( $\Omega$ /Km)	<55.2
Min.Insulation DC Resistance at 20 °C (M $\Omega$ *Km)	200
Rated Temperature(°C)	80
Rated Voltage (V)	60