

# #4134 - Twin OFC Loudspeaker Cable 4.0mm<sup>2</sup>, 25m reel



**Part NO:** #4134

**Product Code:** RGW-1882

**Product Description**

**Reference Standard**

Customer's sample spec.and the general standard

**Multi-construction**

**2Cores**

**Cable Construction**

<b>Conductor</b>	<b>Bare Copper</b>
Construction	0.1 ± 0.008 x 73 x 7
Standard Dia.(mm)	3.02
<b>Insulation</b>	<b>Trans PVC</b>
Thickness	1.0
Insulation Dia.(mm)	5.0 ± 0.1 x 2C
Insulation Color	Trans PVC

**Marking**

Colour Stripe (Black) on one side for identification

**PACKAGING**

25M/Reel

**RoHS GUIDELINE**


We operate according to the following standards

Control Item	Standard	Testing Method	Testing Equipment
Cadmium content (Cd)	<0.01%	EN1122	ICP-AES
Lead content (Pb)	<0.1%	EPA3050B	ICP-AES
Mercury content (Hg)	<0.1%	EPA3052	ICP-AES
Chromium (VI) content	<0.1%	EPA3060(UN-VIS)	ICP-AES
Polybrominated Biphenyls (PBB)	Forbidden	GC/MS	
Polybrominated Diphenyl Ether (PBDE)	Forbidden	GC/MC	

**Revision History**

A0-1

**Design**

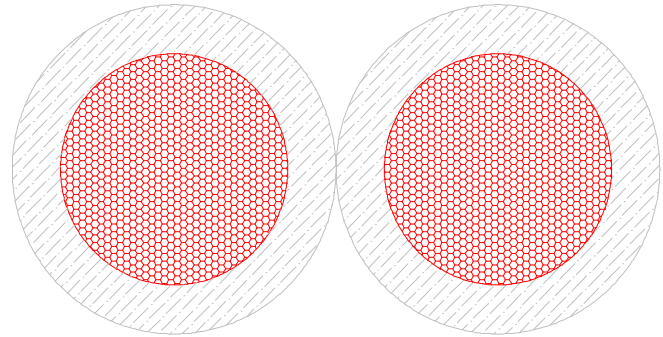

**A: Electrical Characteristics**

Max.Conductor DC Resistance at 20°C ( Ω /Km)	<4.64
Min.Insulation DC Resistance at 20°C ( MΩ *Km)	>200
Rated Temperature(°C)	80
Rated Voltage (V)	300
Capacitance (pF/m)	40 +/- 5
Inductance	0.50μH/m

**Date:** 2013-03-06

**Page:** 1 / 1