


# Datasheet

## CCTV Power Supply 24Vac Range

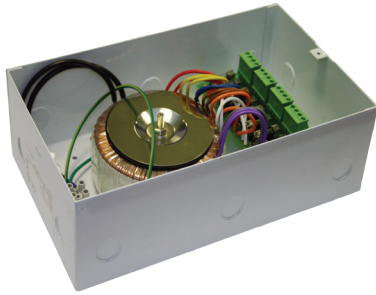

### Features

- UK AC Mains Input
- Metal Case Enclosure
- Multiple fused 24Vac Outputs
- Wall Mountable
- 10 Side Knockouts for Cable entry
- MTBF >50,000 hours

RS Stock Number	Manufacturers P/N	No. of Outputs	Output Voltage	Output Current (Min)	Output Current (Max)
8280119	T4637AD	4	24Vac	0A	4 x 1A
8280112	T4510AD	4	24Vac	0A	4 x 2A
8280116	T4214KE	8	24Vac	0A	8 x 0.5A
8280125	T4511AD	8	24Vac	0A	8 x 1A
8280128	T4512AD	8	24Vac	0A	8 x 2A

### Input

- Rated Input 230-240Vac
- Rated Input Frequency 50Hz
- Leakage Current >0.25mA
- Efficiency 90%

### Environmental

- Operating Temperature 0°C to 40°C
- Storage Temperature -20°C to 70°C

### Casing

- Dimensions 250mm x 150mm x 80mm
- Weight 2.7Kg (approx.)

