

## TECHNICAL FILE


### PIPE WRENCH





EGA Master manufactures a high quality range of Chain Pipe Wrenches, where it is worth pointing out these two models: reversible chain pipe wrench and heavy duty reversible chain pipe wrench.

The reversible pipe wrench has drop forged steel handle and jaw. Ideal for use in confined spaces. A double jaw system gives fast, ratchet-like action in either direction.

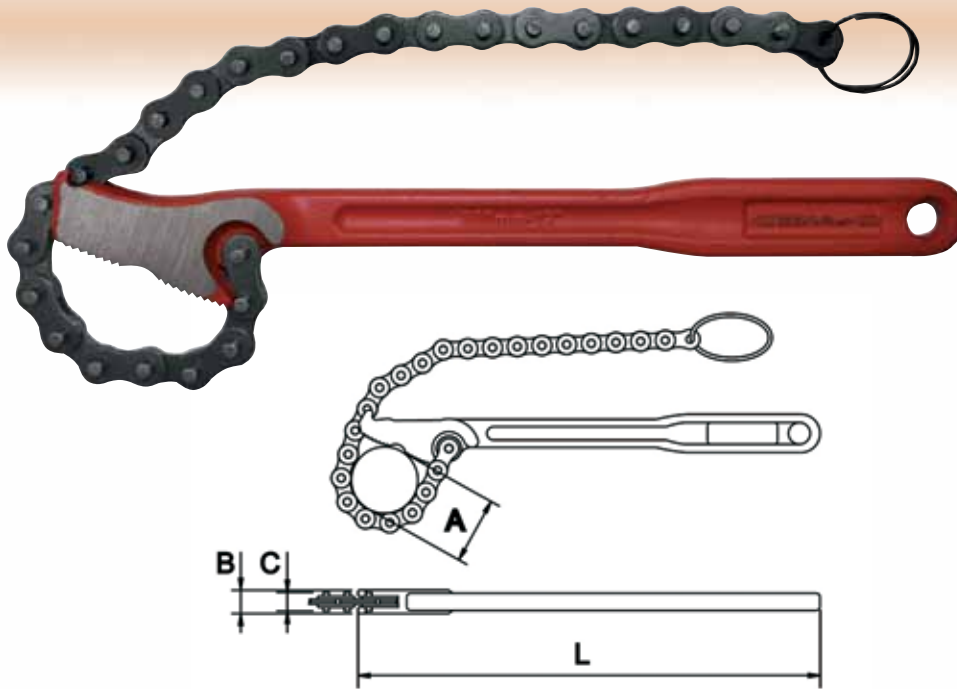The heavy duty reversible chain pipe wrench is the ideal product for the most demanding industry. Its forged handle and jaw give high resistance, when tightening, and security, due to its strong frame.




**REVERSIBLE CHAIN PIPE WRENCH**


<b>COD</b>	L	A	B	C	 Kg.	
61035	300	4"	19	19	0.8	64038

GGG-W-00651e Type III Class A

MATERIAL	HANDLE	DROP FORGED STEEL
	CHAIN	SPECIAL STEEL
HARDNESS	GENERAL HANDLE	30-45 HRc
	TEETH OF HANDLE	50-62 HRc
FINISHING	HANDLE	PAINTED IN EPOXI POWDER RED COLOR RAL-2002 SEMI-TEXTURIZED
	CHAIN	BLACK FINISH

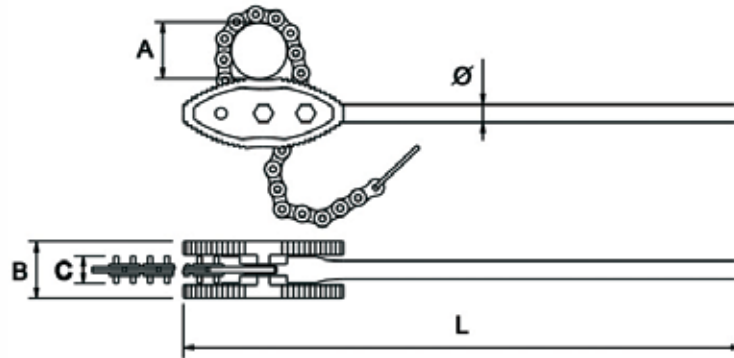

### HEAVY DUTY REVERSIBLE CHAIN PIPE WRENCH

COD	L	A	B	C	FLEXION TEST	Kg	
61036	900	4"	65	36	1600 Nm	5.5	64081
61037		6"			1730 Nm	6.5	64082
61038	1100	8"	70		2280 Nm	12	64083
61039		10"			2500 Nm	13	64084
61138	1300	12"			2850 Nm	17	64128
61139		16"		3450 Nm	19	64129	
62050		18"		5650 Nm	21	64906	
62051		20"		38	5650 Nm	23	64907

GGG-W-00651e Type III Class A

MATERIAL	HANDLE	DROP FORGED STEEL
	CHAIN	DROP FORGED STEEL
HARDNESS	GENERAL HANDLE	33-40 HRc
	TEETH OF HANDLE	52-60 HRc
FINISHING	HANDLE	PAINTED IN EPOXI POWDER RED COLOR RAL-2002 SEMI-TEXTURIZED
	CHAIN	BLACK FINISH