


SIP Ferrua RC2/24 ITEM NO: 06457

SIP Ferrua RC2/50 ITEM NO: 06459

The RC2/24 and RC2/50 – part of SIP's Ferrua line - are designed for any and all applications where space is tight, much like our line of vertical compressors. Whether with a 24 or 50 litre receiver, these units perform to an optimal level in garages, workshops, or in mobile environments.

Key Features:

- Built with an efficient cooling system
- External air filters for easy access
- Wheel-mounted for easy movement
- Reliable and accurate twin gauges

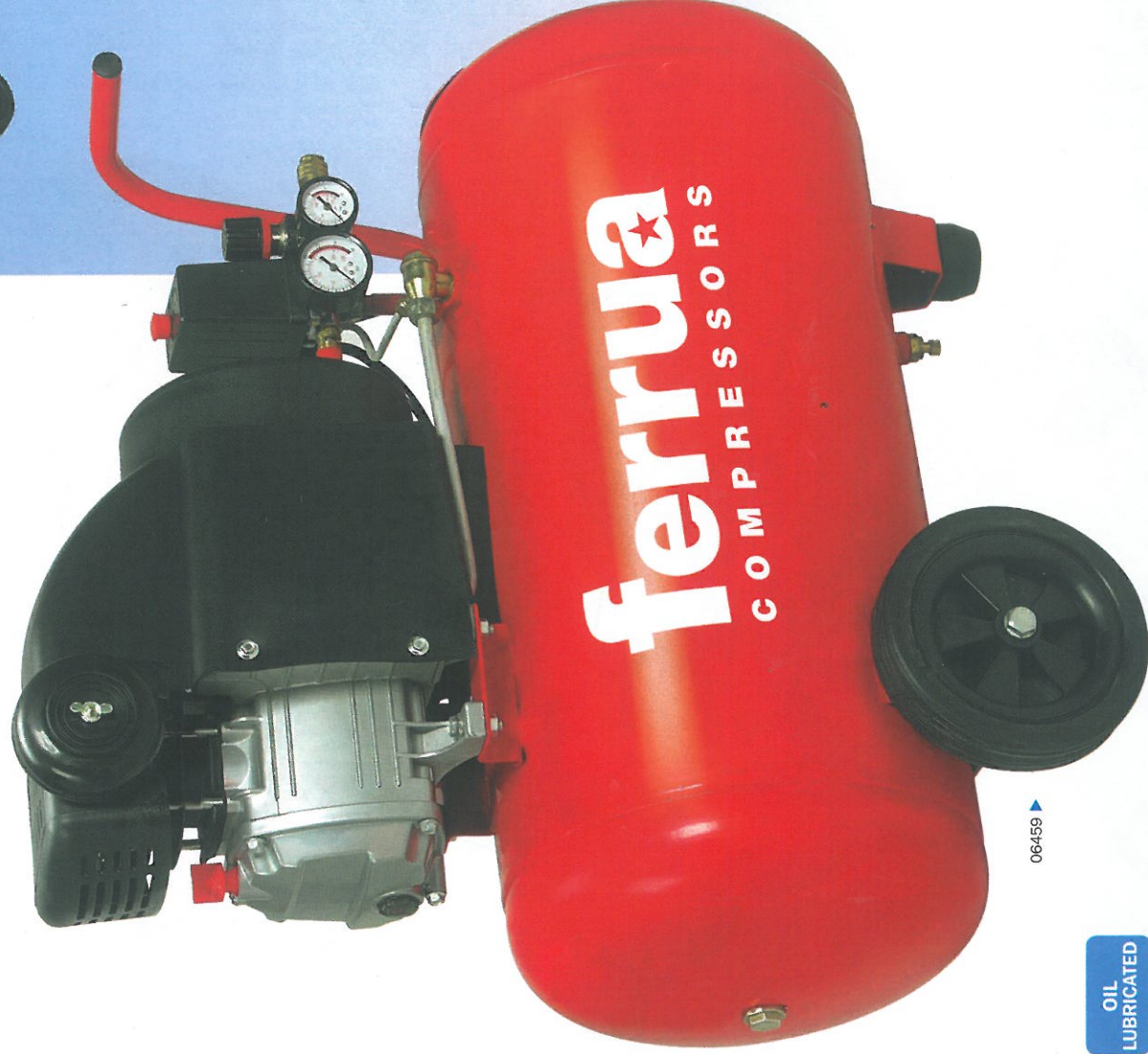

MODEL	SIP Ferrua RC2/24	SIP Ferrua RC2/50
PRODUCT CODE	06457	06459
Input Supply	230 V (13 A)	230 V (13 A)
Motor	2 HP (1.5 kW)	2 HP (1.5 kW)
Air Receiver Size	24 Litre	50 Litre
Piston Displacement	8 CFM (226 Ltr/min)	8 CFM (226 Ltr/min)
Free Air Delivery (FAD)	4.8 CFM (136 Ltr/min)	4.8 CFM (136 Ltr/min)
Maximum Air Pressure	116 psi (8 bar)	116 psi (8 bar)
Noise Level	94 db(A)	94 db(A)
Weight	25 kg	33 kg
Packaged Dimensions	570 x 260 x 580 mm	765 x 325 x 660 mm
Barcode Number	5012713064571	5012713064595