

Industrial Steel Bottle Jacks

▼ Shown: GBJ010A, GBJ030A, GBJ003A



- Lower handle effort reduces operator fatigue
- Fully serviceable
- High-strength beam and pump linkage for long life
- Pumping handle included on all models
- Safety relief valve to prevent overload
- Automatic by-pass port to prevent over-extension
- Wiper seal for extended life
- Thick base material with large area for increased strength and stability during lifting
- Positioning handle on 20 ton through 50 ton models.

GBJ Series



Capacity:

2 - 100 ton


Stroke:

62 - 460 mm



Screw Extension Feature


Heat treated, adjustable extension screw with cleated saddle on selected GBJ models helps adjusting and prevents slipping.

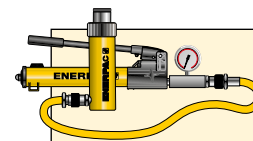

Cylinder-Pump Sets

As an alternative to bottle jacks where the operator is required to stand remote from the jacking point, see our range of cylinder-pump sets.

Page: **58**

| Capacity ton (kN) | Stroke (mm) | Model Number | Screw Extension (mm) | Min. Height (mm) | Max. Height (mm) | Plunger diameter (mm) | Saddle Diameter (mm) | Bottom Dimensions W x L (mm) |  (kg) |
|----------------------|----------------|-----------------|----------------------------|------------------------|------------------------|-----------------------------|----------------------------|---------------------------------------|--|
| 2 (19,6) | 460 | GBJ002LA | - | 570 | 1030 | 29 | - | 75 x 116 | 6,0 |
| 2 (19,6) | 100 | GBJ002A | 165 | 168 | 338 | 24 | 23,5 | 75 x 116 | 3,6 |
| 3 (29,4) | 105 | GBJ003A | 65 | 168 | 338 | 24 | 23,5 | 75 x 116 | 3,7 |
| 5 (49,0) | 150 | GBJ005A | 75 | 212 | 437 | 29 | 28,5 | 75 x 125 | 4,5 |
| 8 (78,4) | 150 | GBJ008A | 75 | 219 | 444 | 37 | 38,0 | 90 x 114 | 6,2 |
| 10 (98,0) | 150 | GBJ010A | 75 | 219 | 444 | 37 | 38,0 | 90 x 114 | 6,4 |
| 10 (98,0) | 62 | GBJ010SA | 30 | 131 | 223 | 37 | 38,0 | 90 x 114 | 5,0 |
| 15 (147,0) | 150 | GBJ015A | 75 | 228 | 453 | 45 | 45,0 | 112 x 163 | 8,8 |
| 20 (196,0) | 150 | GBJ020A | 75 | 234 | 459 | 51 | 61,0 | 120 x 172 | 10,6 |
| 20 (196,0) | 105 | GBJ020SA | 55 | 190 | 350 | 51 | 61,0 | 120 x 172 | 9,5 |
| 30 (294,0) | 150 | GBJ030A | 75 | 242 | 467 | 58 | 69,0 | 144 x 196 | 15,5 |
| 50 (490,0) | 150 | GBJ050A | - | 252 | 402 | 80 | 80,0 | 180 x 230 | 27,0 |
| 100 (980,0) | 150 | GBJ100 | - | 300 | 450 | 110 | 94,0 | 296 x 333 | 87,0 |

All GBJ Jacks meet or exceed: ANSI, PALD, CE.

▼ Enerpac heavy-duty bottle jacks make lifting loads easier.

