


# air reservoir CRVZS-2

Part number: 160236

FESTO

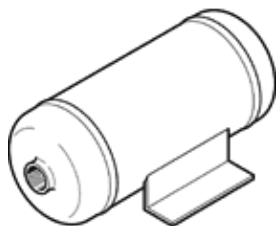

## Data sheet

| Feature                                   | Value  |
|---|--|
| Volume                                    | 2 l  |
| Assembly position                         | Any  |
| Conforms to standard                      | AD 2000 reference sheet  |
| Operating pressure                        | -0.95 ... 16 bar   |
| Certificate issuing department            | TSSACRN0H17477.5C  |
| Operating medium                          | Compressed air in accordance with ISO8573-1:2010 [-:-:-]<br>Nitrogen |
| Corrosion resistance classification CRC   | 3 - High corrosion stress  |
| Food-safe                                 | See Supplementary material information                               |
| Medium temperature                        | -10 ... 100 °C   |
| Ambient temperature                       | -10 ... 100 °C   |
| Authorisation                             | CRN<br>TÜV   |
| Max. tightening torque, connecting thread | 55 Nm  |
| Product weight                            | 1,681 g  |
| Mounting type                             | with through hole  |
| Pneumatic connection                      | G1/2   |
| Materials note                            | Free of copper and PTFE<br>Conforms to RoHS                          |
| Material of air reservoir                 | High alloy steel, non-corrosive                                      |