


**solenoid coil**  
**MH-2-24VDC-PA**  
 Part number: 549906

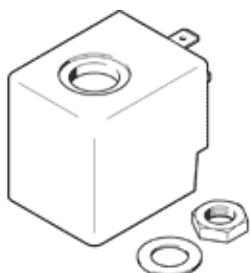

**Data sheet**

<b>Feature</b>	<b>Value</b>
Assembly position	Any
Switching position indicator	No
Min. pickup time	12 ms
Duty cycle	100%
Power factor cos {phi}	0.7
Characteristic coil data	24 V DC: 7.9 W
Permissible frequency fluctuation	+/- 10 %
Permissible voltage fluctuation	+/- 10 %
Protection class	IP65
Ambient temperature	-20 ... 50 °C
Max. tightening torque for fitting	2 Nm
Product weight	150 g
Electrical connection	Per DIN EN 175301-803
Mounting type	with lock nut
Materials note	Contains PWIS substances
Material solenoid coil	Duroplast Copper Steel
Material winding	Copper