


solenoid coil

VACN-N-A1-3A

Part number: 8029135

FESTO

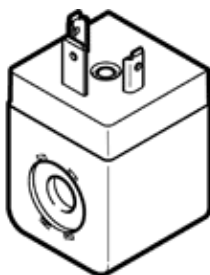

Data sheet

Feature	Value
Type of actuation	electrical
Assembly position	Any
Duty cycle	100%
Insulation class	F
Enamelled wire insulation class	F
Characteristic coil data	230 V AC: 50 Hz, pick-up power 6.2 VA, holding power 3.7 VA 230 V AC: 60 Hz, pick-up power 4.9 VA, holding power 2.9 VA
Surge strength	4 kV
Degree of contamination	3
Permissible voltage fluctuation	+/- 10 %
Certificate issuing department	DNVGL-TAA000011J
CE mark (see declaration of conformity)	to EU directive low-voltage devices
Corrosion resistance classification CRC	2 - Moderate corrosion stress
Protection class	IP65
Ambient temperature	-20 ... 60 °C
Maritime classification	see certificate
Product weight	95 g
Electrical connection	Per DIN EN 175301-803 Plug pattern type A to EN 175301-803
Mounting type	With knurled nut
Materials note	Conforms to RoHS
Material housing	Plastic Steel
Material electrical contact	Brass
Material winding	Copper