




Shrinkable markers "Continuous Tube", thermal transfer

TULT – 3:1 Military and Electronics

TULT is a UL recognized 3:1 heat shrink marker material supplied as a continuous tube and printable on both sides. TULT's polyolefin compound has good mechanical strength and resistance to organic solvents and chemicals. The surface of the tubing has been especially prepared so that print performance is excellent at all times. HellermannTyton's printer range allow users to create a high quality print. In addition it is possible to either perforate the tubing at pre-determined lengths or fully sever the markers.

Features and benefits

- Shrink ratio 3:1
- Available in black, blue, red, white and yellow
- Cable range from 39 mm to 1 mm
- Good mechanical strength and resistance to organic solvents and chemicals
- Highly flexible
- Delivery in convenient storage boxes

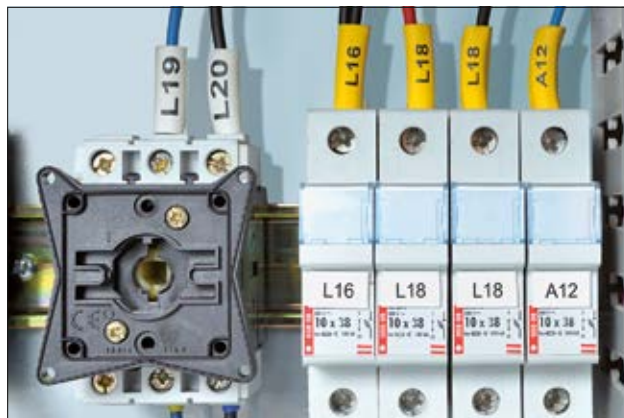

TULT – 5 colours of UL recognised printable tube to cover a wide range of diameters.

MATERIAL	Polyolefin, cross-linked (PO-X)
Operating Temperature	-55 °C to +135 °C
Min. Shrink Temperature	+90 °C
Shrink Ratio	3:1
Recommended Ribbon Type	TTRC+, TTDTHOUT, TTRW, TT822OUT8
Thermal Transfer Printer	TT430, TT4030, TrakMark DS

RoHS



For size matrix please refer to page 439.

TYPE	Supplied Ø D min.	Recov. Ø d max.	Wall (WT)	Pack Cont.	Colour	Article-No.
TULT3-1BK	3.0	1.0	0.60	176 m	Black (BK)	553-40352
TULT3-1BU	3.0	1.0	0.60	176 m	Blue (BU)	553-40353
TULT3-1RD	3.0	1.0	0.60	176 m	Red (RD)	553-40354
TULT3-1WH	3.0	1.0	0.60	176 m	White (WH)	553-40351
TULT3-1YE	3.0	1.0	0.60	176 m	Yellow (YE)	553-40350
TULT4.8-1.6BK	4.8	1.6	0.65	110 m	Black (BK)	553-40452
TULT4.8-1.6BU	4.8	1.6	0.65	110 m	Blue (BU)	553-40453
TULT4.8-1.6RD	4.8	1.6	0.65	110 m	Red (RD)	553-40454
TULT4.8-1.6WH	4.8	1.6	0.65	110 m	White (WH)	553-40451
TULT4.8-1.6YE	4.8	1.6	0.65	110 m	Yellow (YE)	553-40450
TULT6-2BK	6.0	2.0	0.70	110 m	Black (BK)	553-40652
TULT6-2BU	6.0	2.0	0.70	110 m	Blue (BU)	553-40653
TULT6-2RD	6.0	2.0	0.70	110 m	Red (RD)	553-40654
TULT6-2WH	6.0	2.0	0.70	110 m	White (WH)	553-40651
TULT6-2YE	6.0	2.0	0.70	110 m	Yellow (YE)	553-40650
TULT9-3BK	9.0	3.0	0.80	72 m	Black (BK)	553-40952

All dimensions in mm. Subject to technical changes.
Minimum Order Quantity (MOQ) may differ from package content. More colours on request.



For product specific approvals and specifications please refer to the Appendix.

Shrinkable markers "Continuous Tube", thermal transfer

TULT – 3:1 Military and Electronics



TYPE	Supplied Ø D min.	Recov. Ø d max.	Wall (WT)	Pack Cont.	Colour	Article-No.
TULT9-3BU	9.0	3.0	0.80	72 m	Blue (BU)	553-40953
TULT9-3RD	9.0	3.0	0.80	72 m	Red (RD)	553-40954
TULT9-3WH	9.0	3.0	0.80	72 m	White (WH)	553-40951
TULT9-3YE	9.0	3.0	0.80	72 m	Yellow (YE)	553-40950
TULT12-4BK	12.0	4.0	0.85	54 m	Black (BK)	553-41252
TULT12-4BU	12.0	4.0	0.85	54 m	Blue (BU)	553-41253
TULT12-4RD	12.0	4.0	0.85	54 m	Red (RD)	553-41254
TULT12-4WH	12.0	4.0	0.85	54 m	White (WH)	553-41251
TULT12-4YE	12.0	4.0	0.85	54 m	Yellow (YE)	553-41250
TULT18-6BK	18.0	6.0	1.00	26 m	Black (BK)	553-41852
TULT18-6BU	18.0	6.0	1.00	26 m	Blue (BU)	553-41853
TULT18-6RD	18.0	6.0	1.00	26 m	Red (RD)	553-41854
TULT18-6WH	18.0	6.0	1.00	26 m	White (WH)	553-41851
TULT18-6YE	18.0	6.0	1.00	26 m	Yellow (YE)	553-41850
TULT24-8BK	24.0	8.0	1.20	26 m	Black (BK)	553-42452
TULT24-8BU	24.0	8.0	1.20	26 m	Blue (BU)	553-42453
TULT24-8RD	24.0	8.0	1.20	26 m	Red (RD)	553-42454
TULT24-8WH	24.0	8.0	1.20	26 m	White (WH)	553-42451
TULT24-8YE	24.0	8.0	1.20	26 m	Yellow (YE)	553-42450
TULT39-13BK	39.0	13.0	1.25	10 m	Black (BK)	553-43952
TULT39-13BU	39.0	13.0	1.25	10 m	Blue (BU)	553-43953
TULT39-13RD	39.0	13.0	1.25	10 m	Red (RD)	553-43954
TULT39-13WH	39.0	13.0	1.25	10 m	White (WH)	553-43951
TULT39-13YE	39.0	13.0	1.25	10 m	Yellow (YE)	553-43950

All dimensions in mm. Subject to technical changes.
Minimum Order Quantity (MOQ) may differ from package content. More colours on request.



For product specific approvals and specifications please refer to the Appendix.