



## Chimes

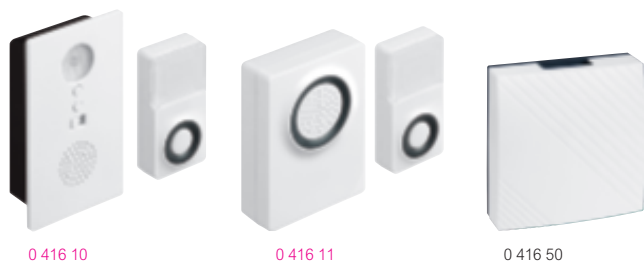

### Pack Cat.Nos Surface-mounting radio-controlled chimes

Pack	Cat.Nos	Surface-mounting radio-controlled chimes
1	0 416 13	<b>230 V chime kit</b> Composition: - weatherproof push-button - receiver Choice of 15 melodies 433 MHz - Range 100 m Configuration via switch to avoid interference
1	0 416 10	<b>8 V chime kit with light indicator</b> Composition: - weatherproof push-button - receiver Choice of 36 melodies 3 adjustable sound levels - Range 100 m 2 x 1.5 V AA alkaline batteries (not included) Preset configuration Wall and table mounting Possibility to connect 4 push-buttons
1	0 416 11	<b>8 V chime kit</b> Composition: - weatherproof push-button - receiver Choice of 36 melodies 2 x 1.5 V AA alkaline batteries (not included) Preset configuration Range 100 m Wall mounting
1	0 416 17	<b>Radio controlled push-button</b> Additional push-button for Cat.No 0 416 10
<b>Electromechanical chimes</b>		
White Dim.: 116 x 116 x 48 mm Tone level: 80 dB at 1 m		
1	0 416 50	<b>8-12 V~ chime</b> Compatible with non-illuminated push-button Cat.No 0 416 46 or illuminated push-buttons Cat.Nos 0 416 45/47 Use a 8 VA transformer Cat.No 0 042 25 or 0 420 25
1	0 416 51	<b>230 V~ chime</b> 2 note chime - 50/60 Hz Compatible with illuminated push-button Cat.No 0 416 45
1	0 416 52	<b>230 V~ chime with transformer</b> 50/60 Hz with built-in 8-12 V transformer Class II Compatible with non-illuminated push-button Cat.No 0 416 46 or illuminated push-buttons Cat.Nos 0 416 45/47

## Bells, bell pushes

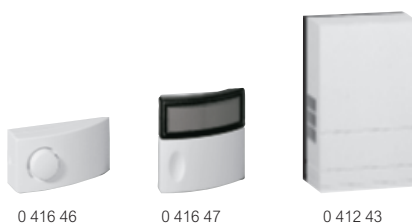

### Pack Cat.Nos Bell pushes

Pack	Cat.Nos	Bell pushes						
		Surface-mounting White Supplied without fixing screws						
5	0 416 46	<b>24 V - 2 A bell push</b> IP 30 - class III W Dim.: 50 x 25 x 20 mm						
10	0 416 45	<b>230 V - 2 A bell push with illuminated label holder</b> IP 30 - class II Supplied without lamp Dim.: 70 x 35 x 24 mm Use lamps Cat.No 0 898 26 - 12 V and Cat.No 0 898 21 - 220 V						
10	0 416 47	<b>24 V - 2 A universal - bell push with label holder</b> Weatherproof IP 44 (IK 07) - Class III W Dim.: 70 x 70 x 25 mm Illuminated with lamp Cat.No 0 898 26 Can be used with any type of chimes (electronic or electromechanical)						
<b>Lido bells</b>								
IP 20 - IK 04 Average acoustic output at 1 m: 80 dB at 1 m Surface-mounting with screws with levelling facilities								
<b>Class II</b> (double insulated)								
		<table border="1"> <thead> <tr> <th>Consumption (mA)</th> <th>Average acoustic output at 1 m in dB</th> </tr> </thead> <tbody> <tr> <td>30</td> <td>80</td> </tr> <tr> <td>45</td> <td>80</td> </tr> </tbody> </table>	Consumption (mA)	Average acoustic output at 1 m in dB	30	80	45	80
Consumption (mA)	Average acoustic output at 1 m in dB							
30	80							
45	80							
10	0 412 21	230 V~ - 50/60 Hz Dim.: 95 x 61 x 33 mm						
1	0 412 43	<b>With built-in transformer</b> 230 V~ - 50/60 Hz Dim.: 135 x 88 x 48 mm Warning: take lamps out of the bell pushes						



Movement detectors,  
see p. 586

