

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1727040005](#)
Status: **Active**
Description: HPD Standard-Density D-Sub Plug Housing, Crimp, Panel Mount, 37 Circuits

Documents:

[RoHS Certificate of Compliance \(PDF\)](#)

[Product Literature \(PDF\)](#)

General

Product Family	D-Sub Products
Series	172704
Exclude SD Check	Yes
IP Rating	IP20
Product Category	Plug
Product Literature Order No	987651-8284
Product Name	HPD
Type	Standard Density
UPC	889056019064

Physical


Circuits (Loaded)	0
Circuits (maximum)	37
Color - Resin	Black
Durability (mating cycles max)	500
Gender	Male
Lock to Mating Part	No
Material - Frame	Tin-plated Steel
Material - Resin	Thermoplastic
Net Weight	0.011/g
Number of Rows	2
Packaging Type	Carton
Panel Mount	Yes
Panel Mount Method	Flange
Polarized to Mating Part	Yes
Ports	1
Shielded	Yes
Temperature Range - Operating	-55° to +130°C
Waterproof / Dustproof	No
Waterproof / Dustproof Type	IP20

Electrical

Current - Maximum per Contact	7.5A
-------------------------------	------

Material Info

Engineering Number	FL37P7-K120
--------------------	-------------

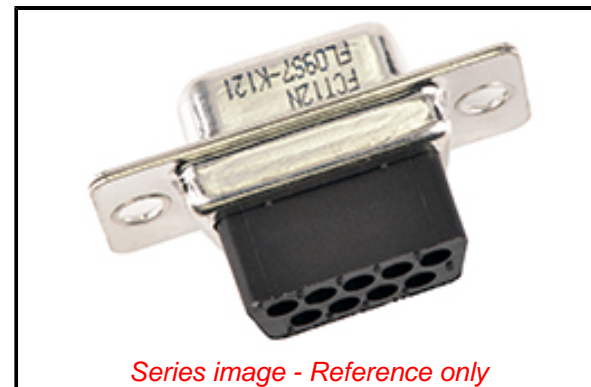

Series image - Reference only

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

Search Parts in this Series

[172704](#) Series

Mates With

D-sub, Size 4, 37 position, Receptacle

Use With

HPD Standard-Density Male Crimp Contacts
[1731120200](#) , [1731120201](#) , [1731120202](#)