


 
 








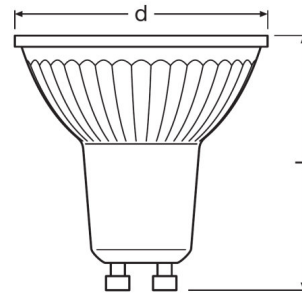





P PAR 16 80 36° 7.2 W/827 K GU10



Product code 4052899958005

	GU10
	55.0 mm
	51.0 mm
	–
W	7.20 W
lm	575 lm
	575 lm
	–
	575 lm
	–
cd	1439 cd
K	2700 K
COLOUR	Warm White
R_a	≥80
t [h]	25000 h
	Yes
V	220...240 V
Hz	50/60 Hz

	100000
	36 °
	1.00 s
	< 0.5 s
	–
Hg	0.0 mg
	A+
	8 kWh/1000h

