

R.5/16 | R 1/4" DRIVE INCH 6-POINT SOCKETS




Norm :


ASME B107.1

Description :

- OGV® profile: more powerful tightening, preserves fasteners.
- Finish: bright chrome.
- Available as rack set (Ref R.40U).

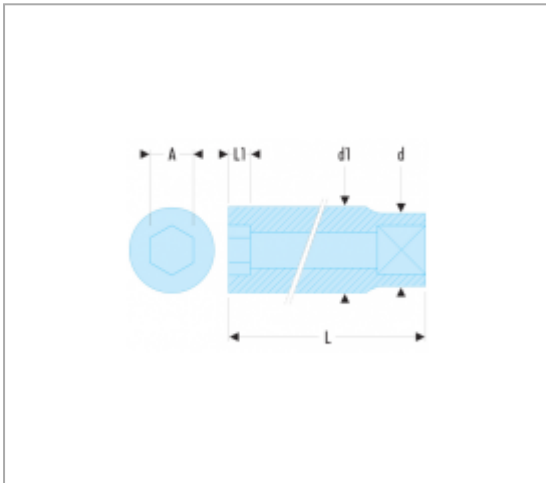

Informations :

	R.5/16
A ["]	5/16
d [mm]	12,0
d1 [mm]	12,0
H3 [mm]	6,50
L [mm]	22
L1 [mm]	6,5
Hex Size [mm]	6
[kg]	0.010