

**Product Code:** 12-1015

**Product Type:** 38cm x 40m Absorbent Roll

**Range:**

**Brand:** Lubetech

**Width (cm):** 38

**Length (cm):** 4000

**Pack Quantity:** 1

**Construction:** SMS

**Comp. GSM:** 17/258/17

**Total GSM:** 275

**Colour MB:** Grey

**Colour SB:** Grey

**Finish Dimpled:** Yes

**Finish Perforated:** Yes

**Pack Weight (kg):** 4.18

**Pack Weight (lbs):** 9.21

**Inline perf dimensions (cm):** 19/19

**Cross perf dimensions (cm):** 40


**Type:** Hydrophilic

**Packaging type:** Box

**Packaging code:** CO-DISPENSER

**Pallet Qty 2.2m high max (LTL):** 30

**Pallet Qty 2.4m high max (FTL):** 30

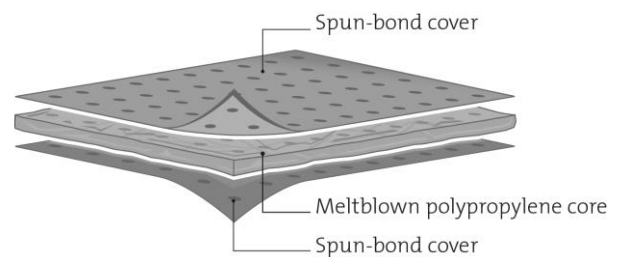

## Features / Benefits:

- The sorbent is made up of two layers that are sonically welded together.
- Top layer is made of a no-lint, durable spun-bond polypropylene.
- Core/base layer is made from high loft melt blown fibres.
- Not as slippery as a fully laminated pad.
- Base layer is low slip making this a great product for foot traffic.
- Roll is perforated along its length.

## Additional Information

Basis weights and recycled content are +/- 5%

Images are provided for illustration purposes only and actual product may vary

Measures absorbency utilising BS 7959-1 2004 / ASTM 726 (long test) with medium viscosity oil and tap water. Statistical average delivered from real time production QC data

Date/version: 16|08|2019 v1.0